

Installation guide

Thermostatic expansion valve

Type TCBE / TCCE / TCAE








068R9552






068R9552

Standard refrigerants:
R407C, R22/407C, R134a, R452A,
R404A/507, R410A, R290*
* (not for TCAE)

Max. working pressure:
PS / MWP: 45.5 bar / 660 psig

Max. test pressure
P_{test} = 45.5 bar / 660 psig

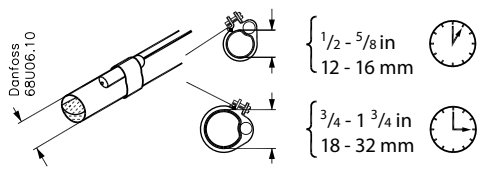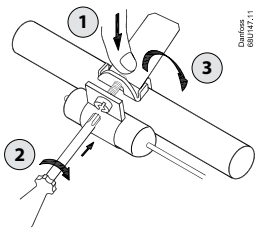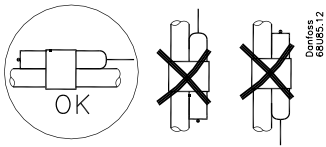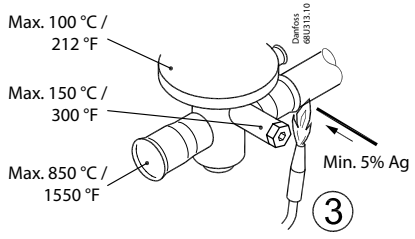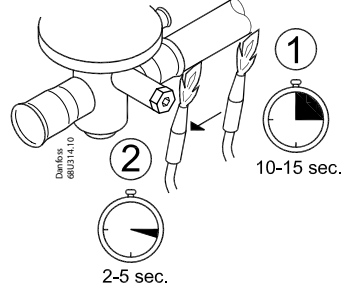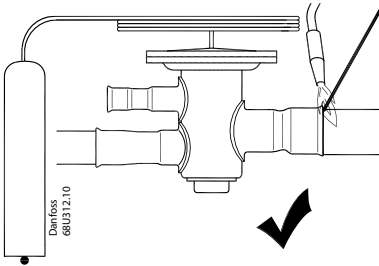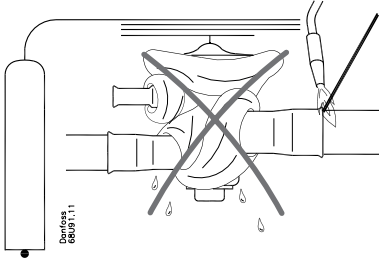

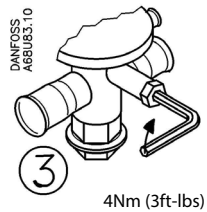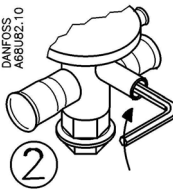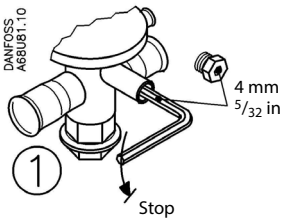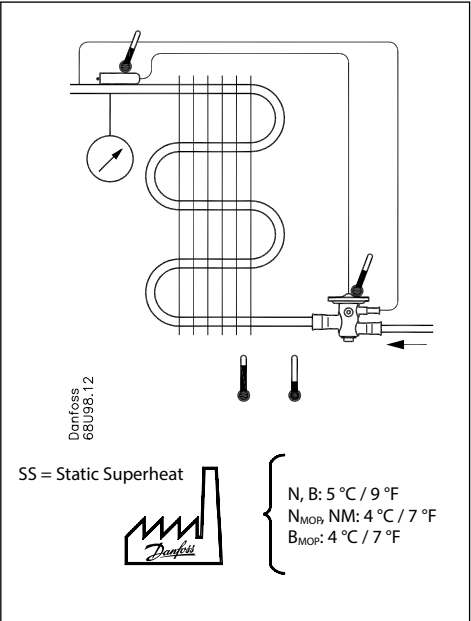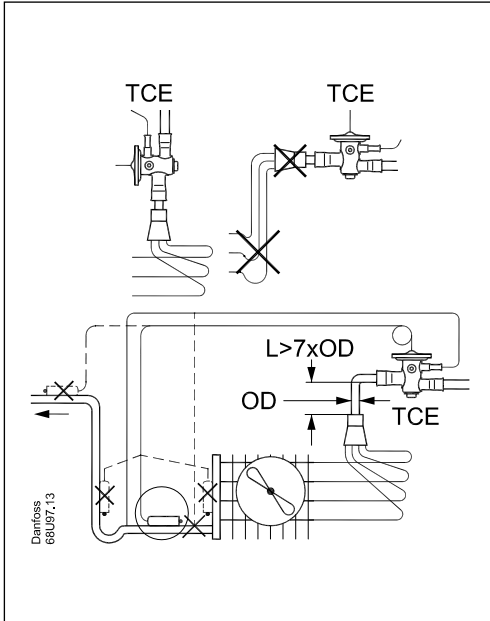

R22/R407C	R134a	R404A/R507	R410A	ΔSS
-	N	-	-	1 × 1 °C (1.8°F)
N	NM	N,B	N,B	1.5 °C (2.7°F)
NM,B	-	NM	NM	2 °C (3.6°F)

Temperature ranges:

- N = -40 - 10 °C / -40 - 60 °F
- NM = -40 - -5 °C / -40 - 25 °F
- B = -60 - -25 °C / -75 - -15 °F