

Installation guide

Pressure operated water valve

Types WVFX 10 – 25 and WVO 10 – 25


003R9743

003R9743

HCFC, HFC and HC

Compliant with ATEX hazard zone 2


PS = 16 bar
MWP = 232 psig

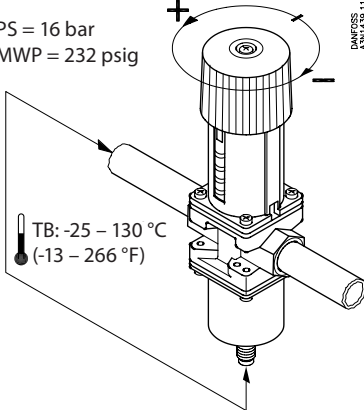

WVFX



PS = 26.4 bar
MWP = 383 psig

PS = 16 bar
MWP = 232 psig

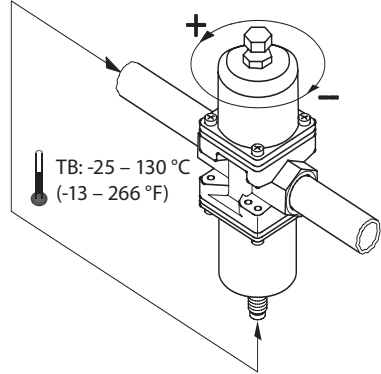

WVO

PS = 26.4 bar
MWP = 383 psig

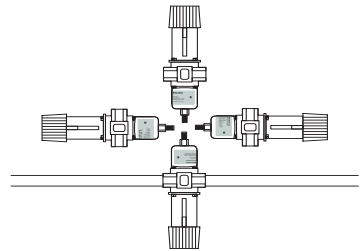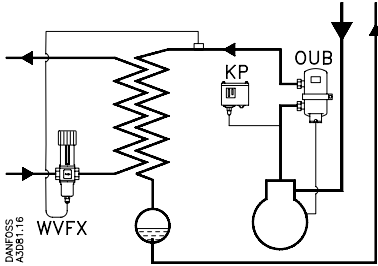

* only WVFX valves

