

Installation guide

ELIMINATOR® Hermetic filter drier

Type DML / DCL

023R9514

023R9514


Refrigerants: R134a, R404A, R407C, R507, R22, R410A and other refrigerants (HCFC, HFC, HFO, HC)	Temperature range: -40 - 70 °C -40 - 160 °F
--	--

	1.5, 03, 05, 08, 16, 30, 60 cu in.	1/4 - 7/8 in. ODM / ODF	PS/MWP 46 bar/667 psig
		1 1/8 in. ODM / ODF	
	38, 41 cu in.	3/4 - 7/8 in. ODM / ODF	PS/MWP 35 bar/500 psig
		1 1/8 in. ODM / ODF	
75 cu in.	3/4 - 1 1/8 in. ODM / ODF		



	03 - 60 cu in.	1/4 - 7/8 in. ODF	PS/MWP 46 bar/667 psig
		1 1/8 in. ODF	
	75 cu in.	7/8 - 1 1/8 in. ODF	

	03 - 75 cu in.	1/4 - 3/4 in.	PS/MWP 46 bar/667 psig
--	----------------	---------------	---------------------------

Soldering

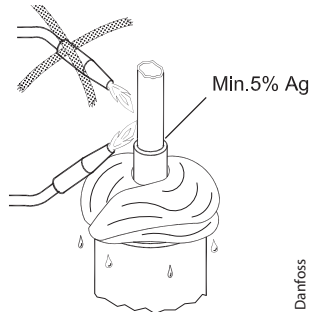

Danfoss
23Z7016.10

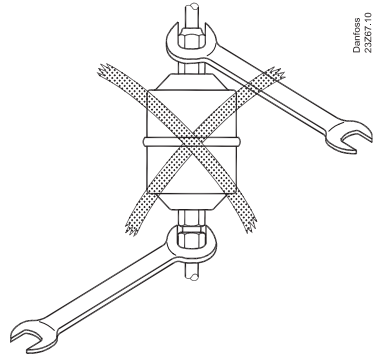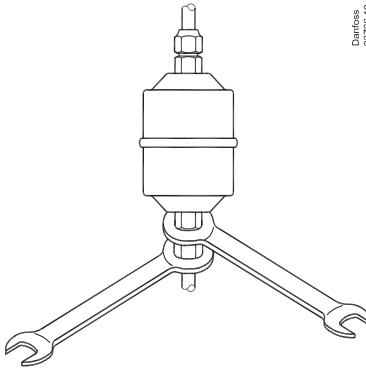

After charging, mark the system with the refrigerant and the oil used.

Mounting

