

Installation guide

ELIMINATOR® Hermetic filter drier Type DMT

023R9546








023R9546

Refrigerant R744 (CO2)

Maximum working pressure	PS/MWP: 140 bar/2030 psig
Refrigerant temperature	T _{min.} : -40 °C / -40 °F
	T _{max.} : 100 °C / 212 °F

Flare / flare o-ring / flare NPT
copper plated solder versions

Connection: All sizes

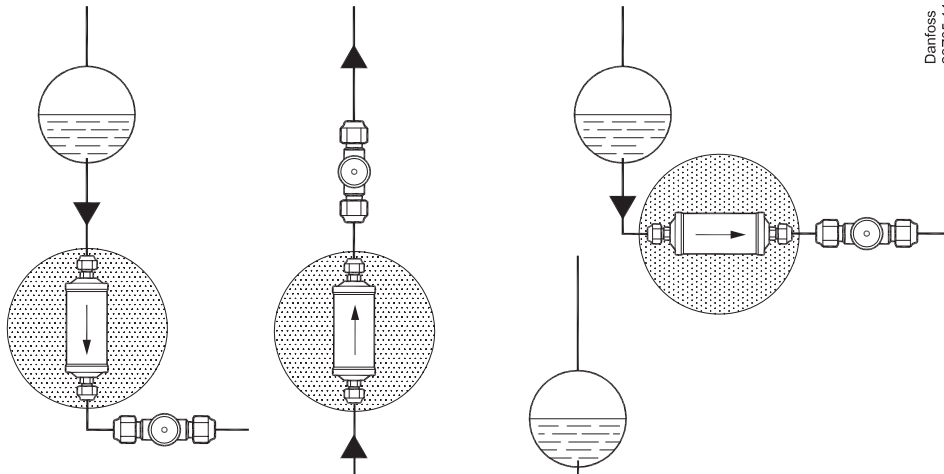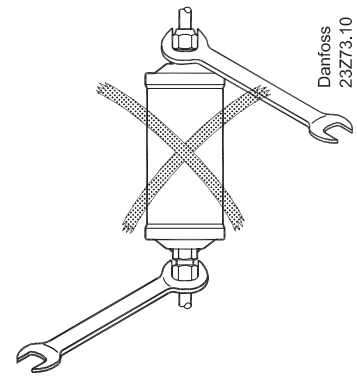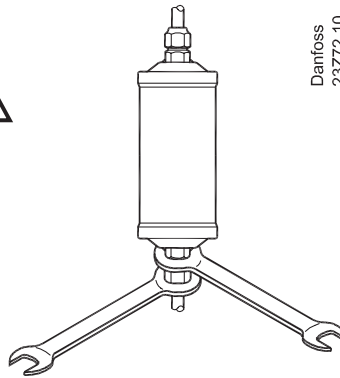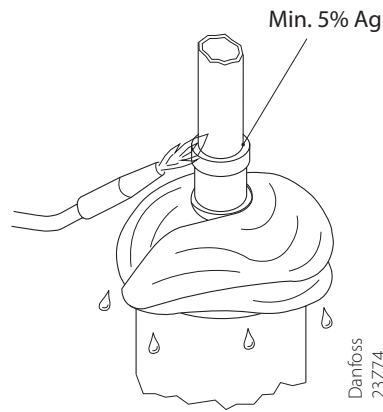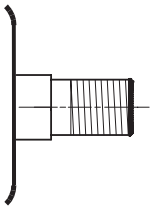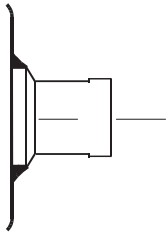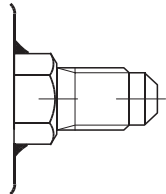

Danfoss
23Z05.11