

Installation guide



ELIMINATOR® Hermetic receiver filter drier

Type DMC and DCC


023R9534

<p>Refrigerants:</p> <p>R134a, R404A, R407C, R507, R22, R410A and other refrigerants (HCFC, HFC, HFO, HC)</p>	<p>Temperature range:</p> <p>-40 – 70 °C -40 – 160 °F</p>	<p>Max. working pressure:</p> <p>PS / MWP = 42 bar / 610 psig</p>
--	--	--

023R9534

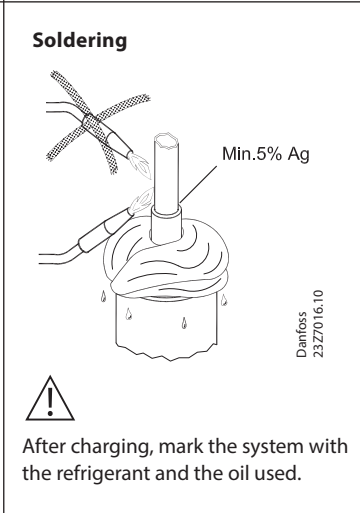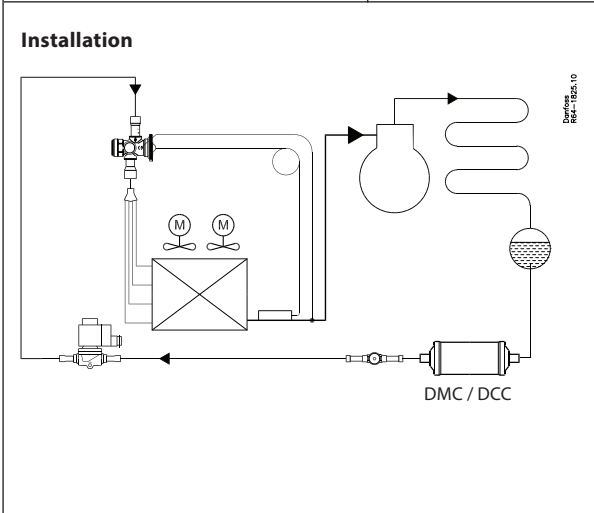

Danfoss
23Z7016.10

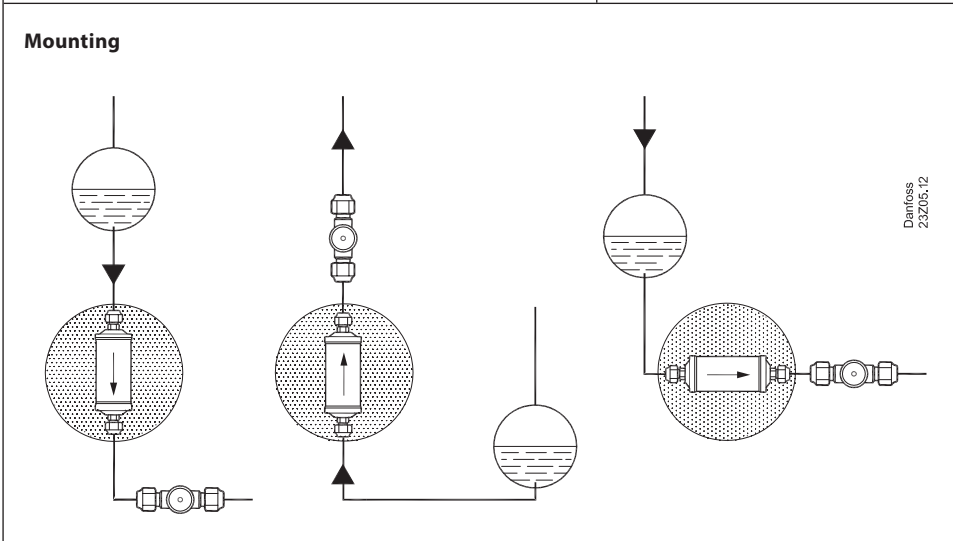

Danfoss
23Z05.12