

Installation guide

Tube-in-tube heat exchanger Type HE



 
015R9711

015R9711

Refrigerants:

HCFC, HFC and HC: HE 0.5 – 1.5
Compliant with **ATEX hazard zone 2**


HCFC and non-flammable HFC: HE 4.0 – 8.0

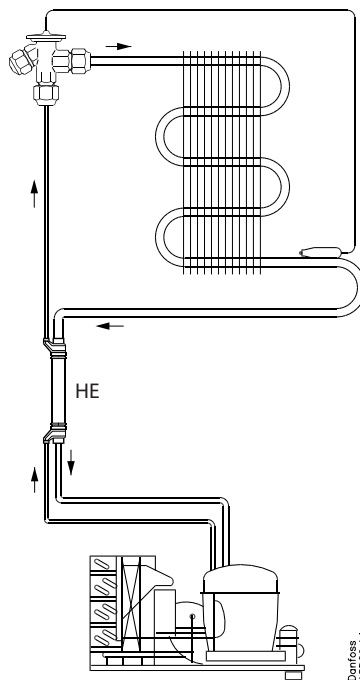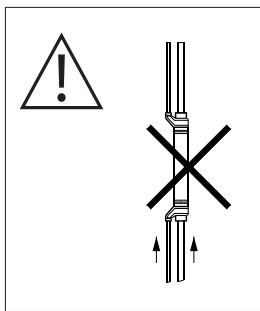

Danfoss
15D29.14

Type	HE 0.5, HE 1.0, HE 1.5, HE 4.0	HE 8.0
Max. working pressure PS/MWP	28 bar/406 psig	21.5 bar/312 psig
Max. test pressure (one time)	40 bar/580 psig	28 bar/406 psig
Temperature range	-60 – 120 °C (-76 – 248 °F)	

Silver flo 55 + Easy flow flux

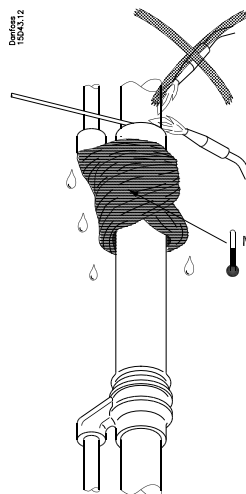

Max. 150 °C
(300 °F)

Max. 150 °C (300 °F)