

# Installation Guide

## Differential pressure valve

### Type NRD

020R9622


**Refrigerants:**  
**HCFC, HFC and HC**

Applicable to all common non-flammable / flammable refrigerants, excluding R717 and to noncorrosive gases / liquids dependent on sealing material compatibility.  
 The design pressure shall not be less than the value outlined in Section 9.2 of ANSI / ASHRAE 15 for the refrigerant used in the system.

**Max. Working Pressure:**  
 PS/MWP = 46 bar (667 psi)

**Media temperature:**  
 Min. -50 °C (-58 °F)  
 Max. 140 °C (285 °F)

020R9622

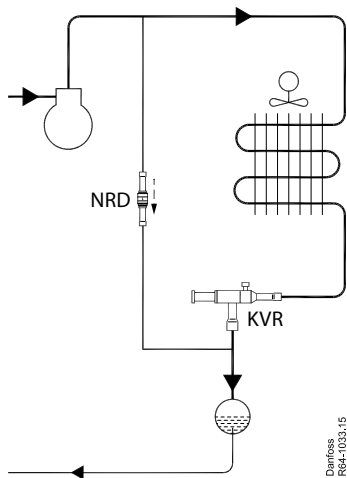

Danfoss  
 REF-10351.15

