

# Installation guide





## Hot gas bypass regulator type CPCE Liquid gas mixer type LG (accessory)

034R9507

034R9507

HCFC, HFC and HC

Compliant with **ATEX hazard zone 2**

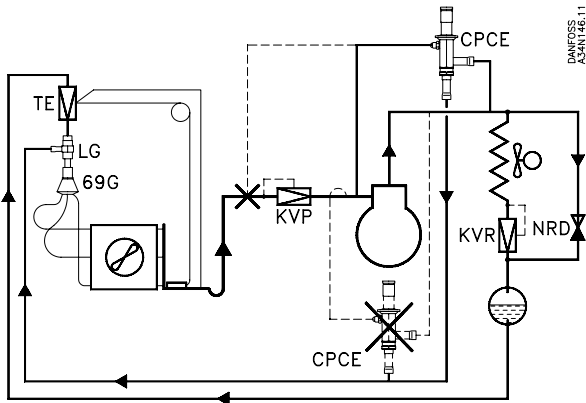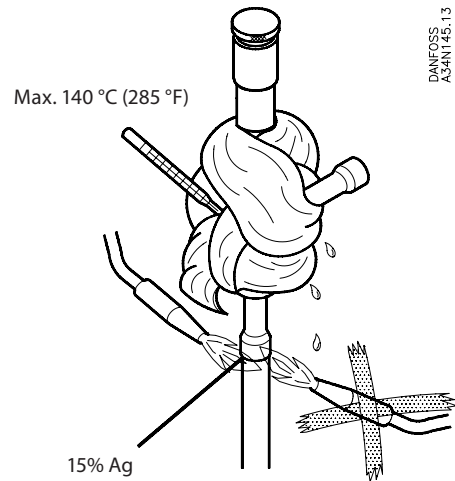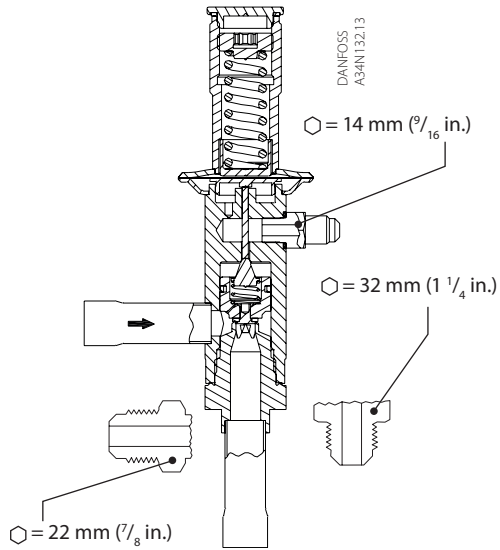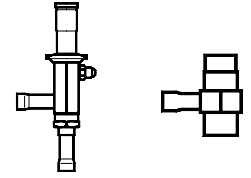

$t_{max.} = 140\text{ °C (285 °F)}$   
 $t_{min.} = -50\text{ °C (-60 °F)}$

PS/MWP = 28 bar  $p_e$  (405 psig)  
 $P_{max. test} = 31\text{ bar } p_e$  (450 psig)

