

## Spare parts and accessories

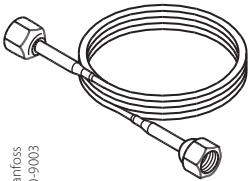
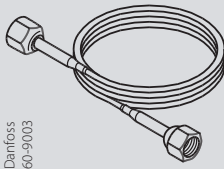
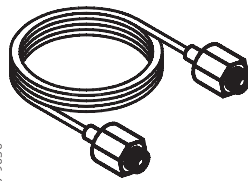
### Pressure switch

### Type KP

Description	Qty.	Code no.
	1	060-008666 <sup>1)</sup>
	1	060-011366 <sup>1)</sup>
	<b>Top cover for single switch</b> 060-109766	
	1	Top plate
	2	Screw
	<b>Top cover for dual switch</b> 060-109866	
	1	Top plate
	2	Screw
	1	060-003166
	1	060-003266
	1	060-033066
	1	060-035066
	<b>Wall bracket</b> 060-105566	
	1	Bracket
	4	Screw, M4 x 6
	4	Washer

 

 

Description	Qty.	Code no.
	<b>Angle bracket</b> 060-105666	
	1	Bracket
	4	Screw, M4 x 6
	4	Washer
	<b>Locking plate with screw</b> 060-018966	
	1	Plate (1)
	1	Screw (2)
	<b>Seal screw for locking plate</b> 060-105766	
	2	060-105766
	<b>Screwed cable entry, Pg 13.5</b> 060-105966	
	1	Cable entry
	1	Nut

<sup>1)</sup> Can be used only if compliance with UL 353 is not needed.

Description	Code no. Multi pack	Code no. Industrial pack	
<b>Capillary tube, copper</b> 1/4 inch or 6 mm flare nut  	21 mm tube "tail"		
	0.5 m	—	060-019066 <sup>1)</sup>
	1.0 m	060-004866	060-019166 <sup>1)</sup>
	1.5 m	—	060-019266 <sup>1)</sup>
	2.0 m	060-016366	060-019366 <sup>1)</sup>
	50 mm tube "tail"		
	0.5 m	—	060-007066 <sup>1)</sup>
	1.0 m	060-017166	060-007166 <sup>2)</sup>
	1.5 m	—	060-007266 <sup>1)</sup>
	2.25 m	060-017666	—
	with Schraeder valve opener		
	0.5 m	—	060-000466 <sup>1)</sup>
	1.0 m	—	060-000566 <sup>1)</sup>
1.5 m	060-002366	—	
<b>Capillary tube, steel</b> not for NH <sub>3</sub>  	1/4 inch or 6 mm flare nut		
	1.0 m	060-016766	—
	1.5 m	060-016866	—
<b>Capillary tube, steel</b> for NH <sub>3</sub>  	M10 x 0.75		
	1.0 m	060-007866	—
	G 3/8 and M10 x 0.75		
1.0 m	060-008266	—	

<sup>1)</sup> 50 pcs.

<sup>2)</sup> 40 pcs.

Description	Qty.	Code no.	
	<b>Nipple</b> M10 x 0.75 / G 1/4 A <b>060-010466</b>		
	Nipple	1	
	Alu gasket	2	
	1	<b>060B121066</b>	
	<b>Weld nipple</b> M10 x 0.75 for NH <sub>3</sub> <b>060-005766</b>		
	Union	1	
	Nipple, OD 6 mm x 150 mm	1	
	Alu gasket	1	
	2	<b>060-104866</b>	