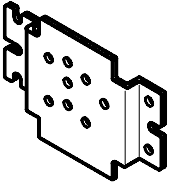
 
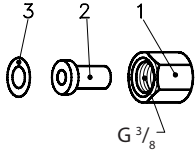
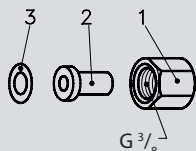
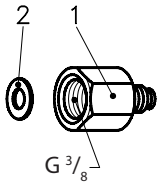
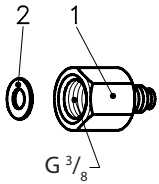

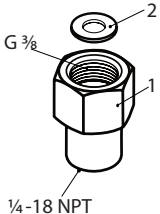
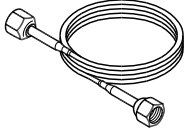
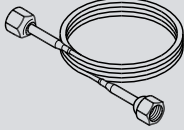
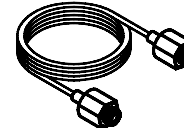


## Spare parts and accessories

# Differential pressure switch Types MP 54, MP 55 and MP 55A

Description	Qty.	Code no.	Description	Code no. Multi pack	Code no. Industrial pack	
	<b>Wall bracket</b>				<b>060-105566</b>	
	Bracket	1				
	Screw, M4 x 5	4				
	Washer	4				
	<b>Angle bracket</b>				<b>060-105666</b>	
	Bracket	1				
	Screw, M4 x 5	4				
	Washer	4				
	<b>Solder nipple for G<sup>3/8</sup></b>				<b>017-436866</b>	
	1. Union	1				
	2. Nipple, ID 8 mm/ OD 10 mm	1				
	<b>Weld nipple for G<sup>3/8</sup></b>				<b>017-422966</b>	
	1. Union	1				
	2. Nipple, OD 10 mm	1				
	<b>Reducer G<sup>3/8</sup> - 1/4 in. flare</b>				<b>017-420566</b>	
	1. Reducer	1				
	2. Alu gasket	1				
	<b>Alu gasket for reducer and nipple</b>				<b>060B120866</b>	
	2. Alu gasket	2				
	<b>Cutting ring coupling for 6 mm steel tube</b>	1			<b>060B121066</b>	
	<b>Adapter 3/8 G x 1/4-18 NPT</b>				<b>060B030266</b>	
	1. Adapter	1				
	2. Alu gasket	1				
	<b>Capillary tube, copper</b> 1/4 in. or 6 mm flare nut					
	21 mm tube "tail"					
	0.5 m	—				<b>060-019066</b> <sup>1)</sup>
	1.0 m	<b>060-004866</b>				<b>060-019166</b> <sup>1)</sup>
	1.5 m	—				<b>060-019266</b> <sup>1)</sup>
	2.0 m	<b>060-016366</b>				<b>060-019366</b> <sup>1)</sup>
	50 mm tube "tail"					
	0.5 m	—				<b>060-007066</b> <sup>1)</sup>
	1.0 m	<b>060-017166</b>				<b>060-007166</b> <sup>2)</sup>
	1.5 m	—				<b>060-007266</b> <sup>1)</sup>
with Schraeder valve opener						
0.5 m	—	<b>060-000466</b> <sup>1)</sup>				
1.0 m	—	<b>060-000566</b> <sup>1)</sup>				
	<b>Capillary tube, steel</b> 1/4 in. or 6 mm flare nut not for NH <sub>3</sub>					
	1.0 m	<b>060-016766</b>				—
	<b>Capillary tube, stainless steel 18/8</b> G <sup>1/2</sup> for NH <sub>3</sub>					
	1.5 m	<b>060-016866</b>				—

<sup>1)</sup> 50 pcs.

<sup>2)</sup> 40 pcs.