



REFRIGERATION AND  
AIR CONDITIONING




# Instructions Protocol interface AK-PI 300



080R9307



R18PV102

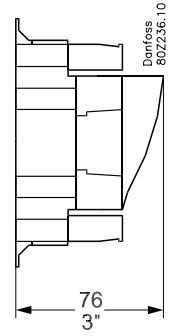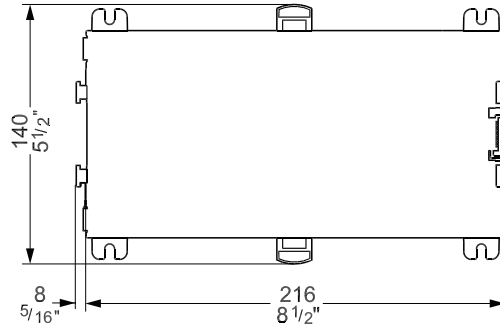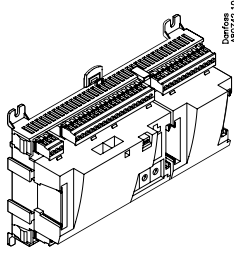


**CE**

-20°C < t<sub>amb</sub> < 55°C  
-0°F < t<sub>amb</sub> < 130°F  
0 - 95% RH, non condensing  
IP10 / VBG4  
UL: E166834

**AK-PI 300 installation:**  
See manual: RS8GP


**Data communication:**  
See literature : RC8AC

## Princip

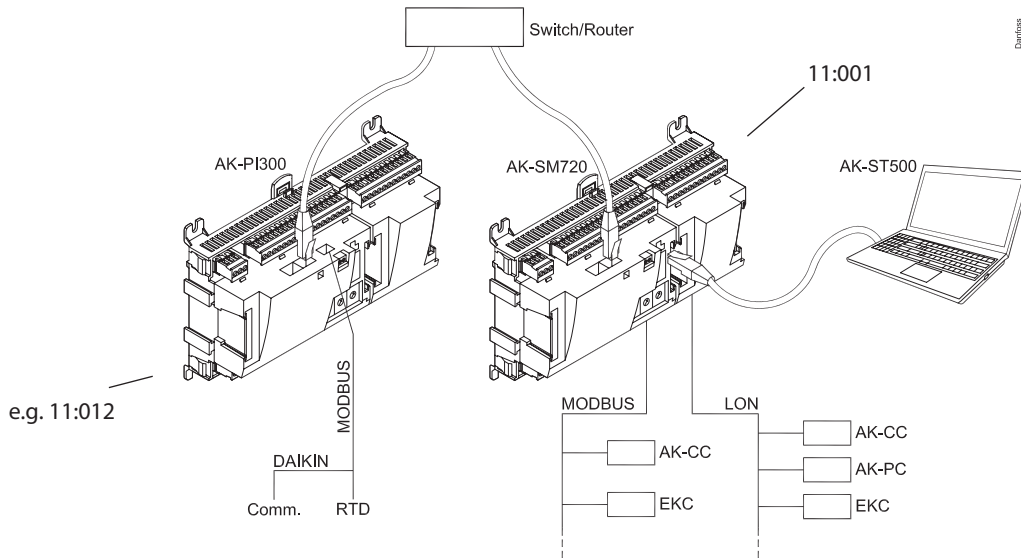


080R9307 11

**Supply voltage:**


Power supply  
Class II 

24 V a.c. / d.c.


The 24 V must not be shared by other controllers or units

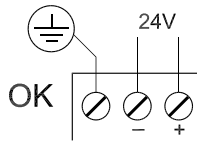

The 24 V input must not have earth connection

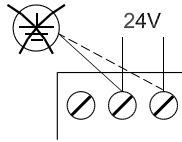



Danfoss  
802206.111

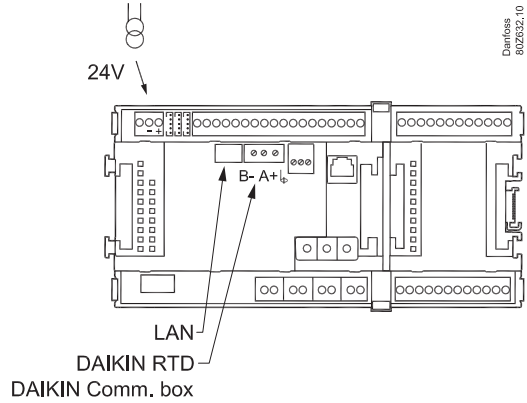

Danfoss  
802052.10

**Address**

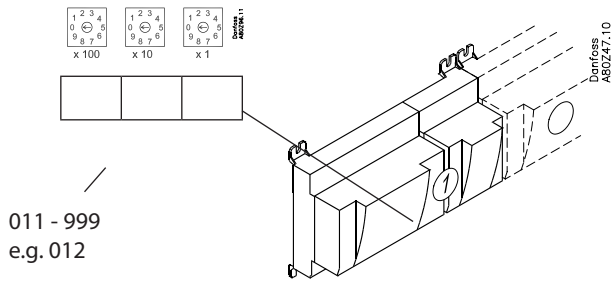

 The Product contains electrical components  
And may not be disposed together with domestic waste.  
Equipment must be separate collected with Electrical and Electronic waste. According to Local and currently valid legislation.

ADAP-KOOL®