
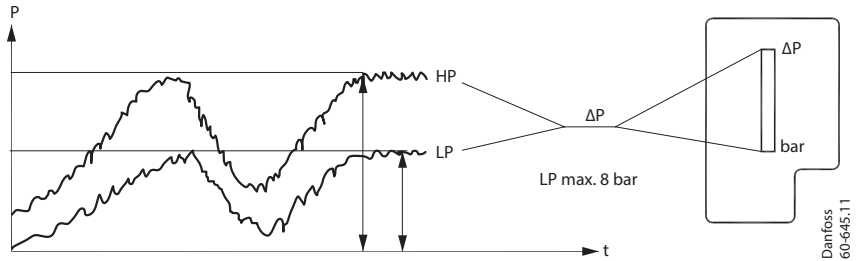



# Installation guide

## Differential pressure switch Type CAS 155





060R9303

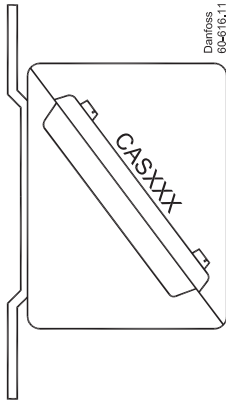

060R9303

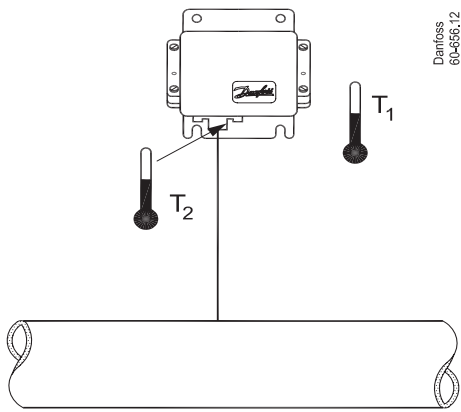

$T_1$  min.: -25 °C  
 $T_2$  min.: -25 °C  
 $T_1$  max.: 70 °C  
 $T_2$  max.: 100 °C (For water and seawater, max. 80 °C)

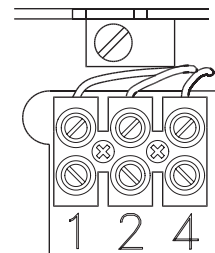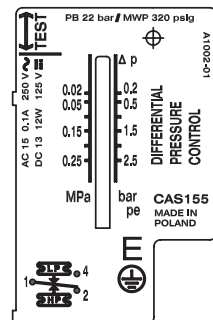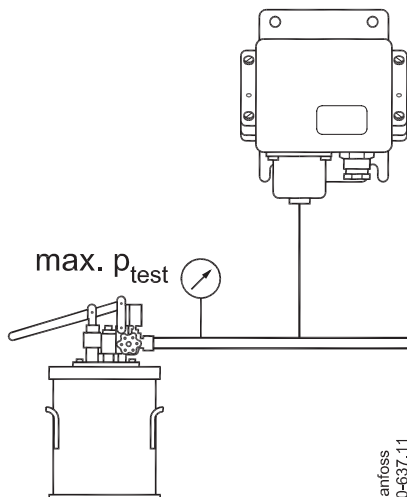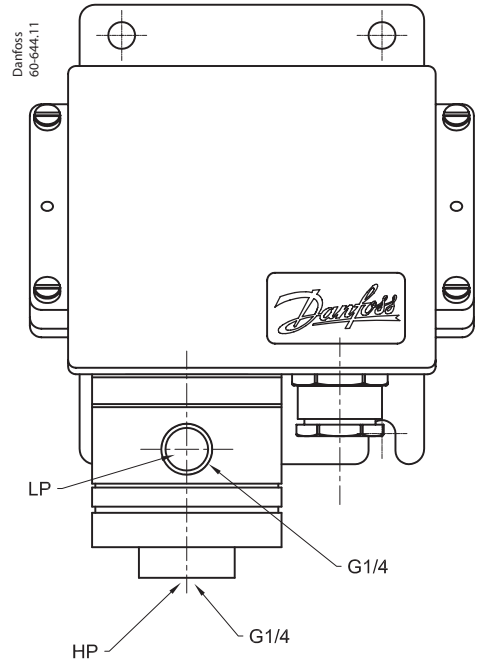

Danfoss  
60L1050.11

