



Installation guide

2-step thermostat Type CAS 1080

060R9326

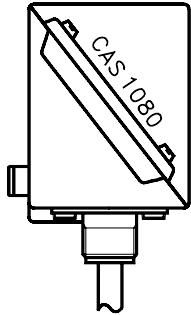

DANFOSS
A60-1118.10

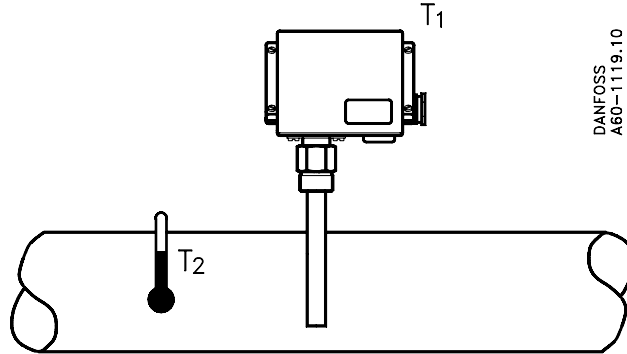


DANFOSS
A60-1119.10

T_2 max. 220 °C

T_1 min. -25 °C
 T_1 max. 70 °C



060R9326

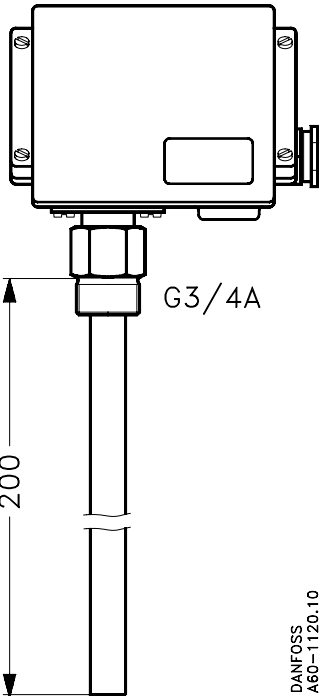


G3/4A

200

DANFOSS
A60-1120.10

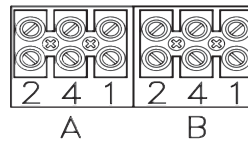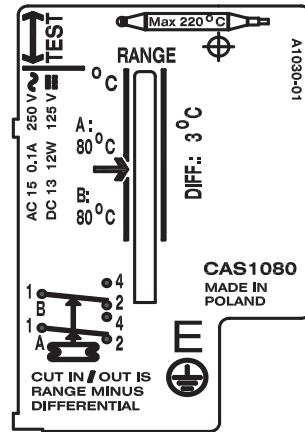

Danfoss
60-1121.16

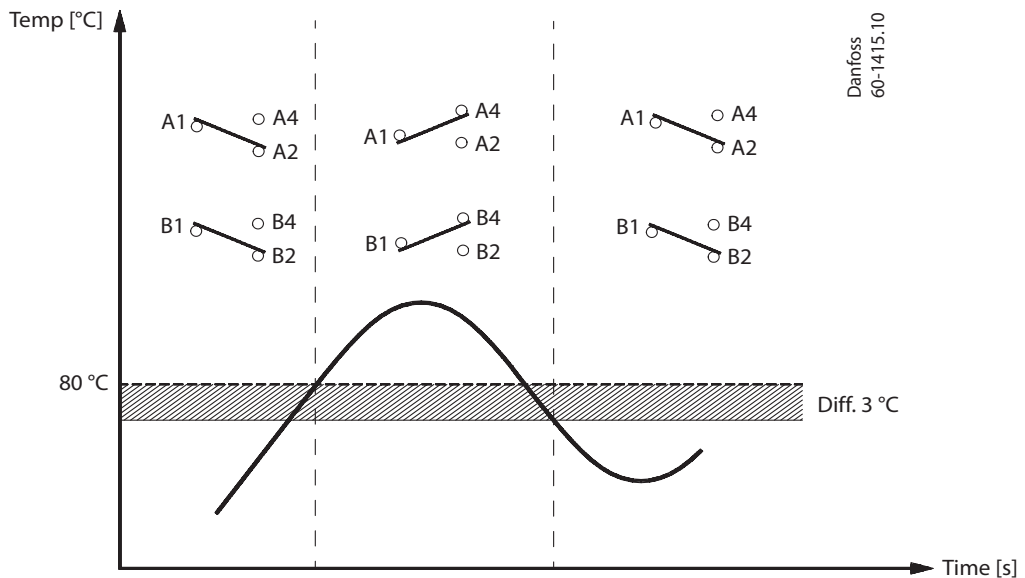

Danfoss
60-1415.10