

Installer Guide

Pressure transmitters MBS 1200 / MBS 1250 Pressure transmitters with pressure and temperature output MBS 1300 / MBS 1350


063R9300

063R9300


Elektrisk tilslutning:
Electrical connection:
Elektrischer Anschluss:
Raccordement électrique:
Conexión eléctrica:
Connessions eletrica:

Se produktskilt
See procut label
Siehe Produktschild
Voir étiquette du produit
Ver la pegatina en el producto
Vedi etichetta sulla convezione

M12 × 1 EN60947-5-2

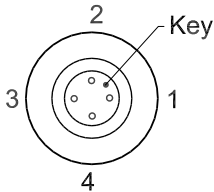


Round Packard Metri-Pack

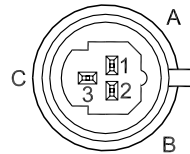


(Not: MBS 1300 / MBS 1350)

Deutsch DT04-4P

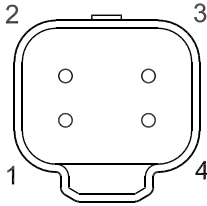


Deutsch DT04-3P

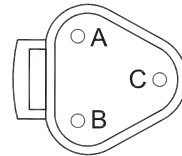


(Not: MBS 1300 / MBS 1350)

EN 175301-803-C Industrial Standard

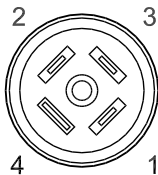

AMP Superseal 1.5

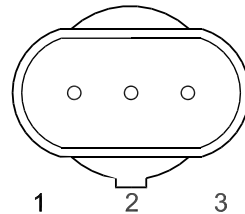

(Not: MBS 1300 / MBS 1350)

Installer Guide

Electronic pressure switch MEP 2200 / MEP 2250 MEP 2600 / MEP 2650


063R9300

063R9300


Elektrisk tilslutning:
Electrical connection:
Elektrischer Anschluss:
Raccordement électrique:
Conexión eléctrica:
Connessions eletrica:

Se produktskilt
See procut label
Siehe Produktschild
Voir étiquette du produit
Ver la pegatina en el producto
Vedi etichetta sulla convezione


M12 × 1 EN60947-5-2

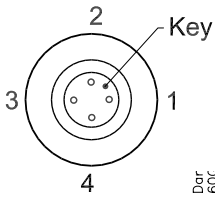

Deutsch DT04-4P

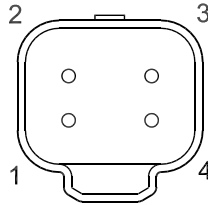

EN 175301-803-C Industrial Standard

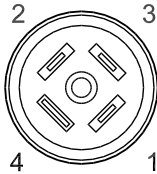

Deutsch DT04-3P

