

Installation Guide

Pressure Transmitters MBS 6300

063R1000

063R1000





Electrisk tilslutning:	Se produktskilt
Electrical connection:	See product label
Elektrischer Anschluss:	Siehe Produktschild
Raccordement électrique:	Voir étiquette du produit
Conexión eléctrica:	Ver la pegatina en el producto
Connessione elettrica:	Vedi etichetta sulla confezione



Materials	Polyolefin cable Screen (Cu-Sn) Insulation ETFE
Electrical connection, 4–20 mA output 2 wire	Red wire: + supply White wire: - supply Red/black wire: Not used White/black wire: Not used Screen: Not connected to MBS housing
Electrical connection, ratiometric output and absolute voltage output	Red wire: + supply White wire: - supply Red/black wire: Output White/black wire: Not used Screen: Not connected to MBS housing

Screened cable Ø4.9

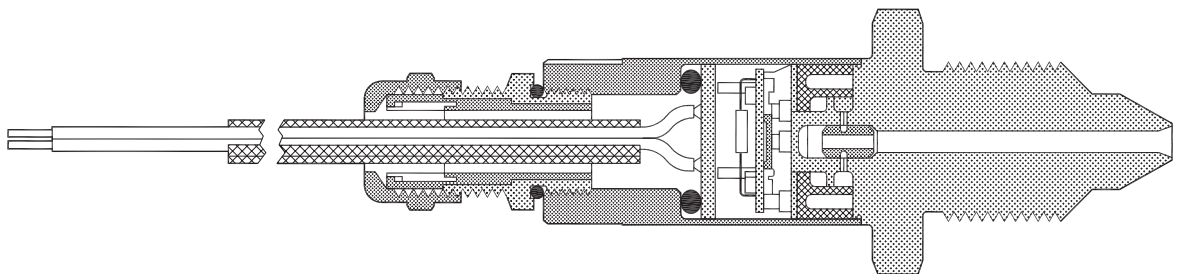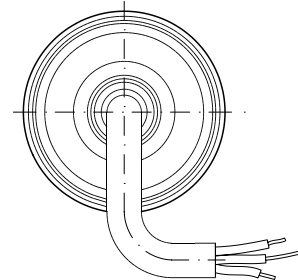

Female part:

Recommended hardness:	[HRC] 50 or higher
Recommended mounting torque:	30 Nm

