

Instruction




032R9340


032R9340

EV210A 1.2 - 3.5B, NC
 EV210A 1.5 - 3.5B, NO
 EV210A 1.2 - 3.5SS, NC


NC

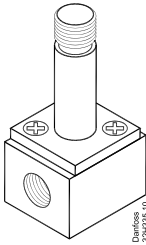


NO

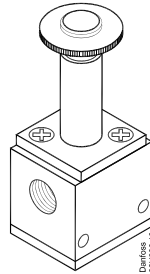


EV210A 2 B G18 /
 F NC 000 /
 032HXXXX / WWY /
 made in XXXXXXX

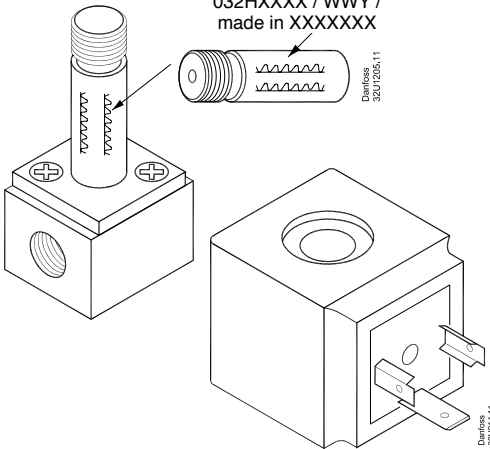

T = 30°C → +120°C (EPDM)
 T = 10°C → +100°C (EPDM) min. ΔP max.

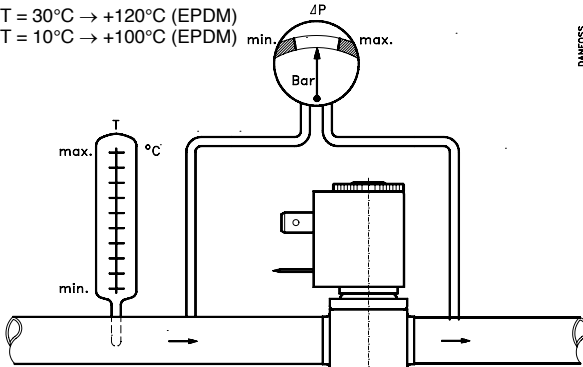


DANFOSS
 A32H11.10

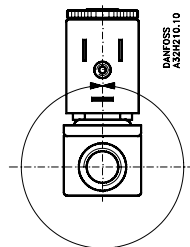

DANFOSS
 A32H11.10

Spare parts NC

- 1) Armature tube
- 2) Armature with valve plate and spring
- 3) Flange
- 4) Disk
- 5) O-ring
- 6) Nut
- 7) 2 screws for connecting tube to valve body

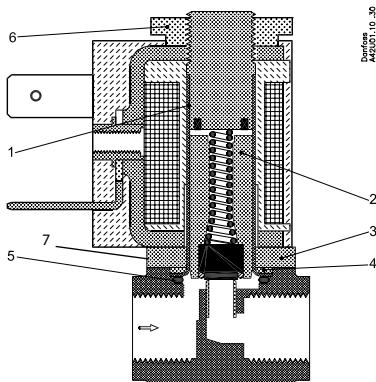

Seal material	Code No.
EPDM	042U0067
FKM	042U0068