




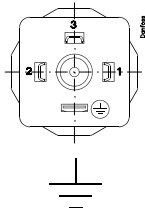
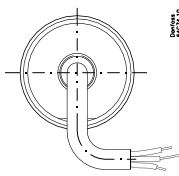
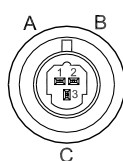

 

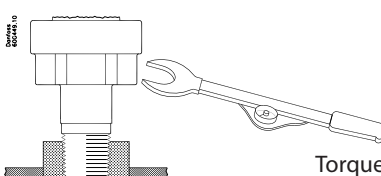
# Instructions



064R9301

064R9301

## Pressure Transmitters MBS 1900

  	<p>Elektrisk tilslutning: ..... Se produktskilt          Electrical connection: ..... See product label          Elektrischer Anschluss: ..... Siehe Produktschild          Raccordement électrique: ..... Voir étiquette du produit          Conexión eléctrica: ..... Ver la pegatina en el producto          Connessione elettrica: ..... vedi etichetta sulla confezione</p>		
	<p>EN 175301-803</p>  <p>Ikke forbundet til kapsling          Not connected to enclosure          Kein Anschluss an Gehäuse          Pas connecté au boîtier          No conectado a la cubierta          Non collegato al corpo</p>	<p>2 m cable</p> 	<p>Round Packard metripack 150.2</p> 
			
	 <p>Torque max. 20Nm</p>		