


# TL5CNK LBP/MBP Condensing Unit R290 (Propane) 220-240V 50Hz

## Data Sheet

### General

<b>Condensing unit</b>		<b>TL5CNK</b>
Version	Size	Code number
<b>N0</b> - for capillary tube	<b>BG1</b>	114F1504

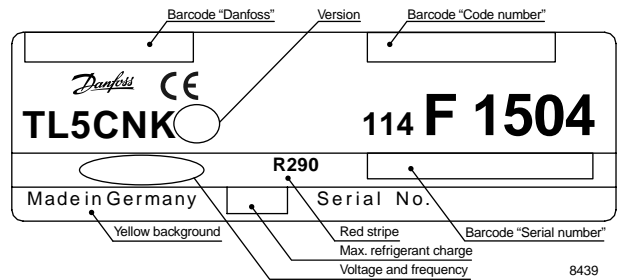

### Application

Application		LBP/MBP
Evaporating temperature range at 32°C °C		-40 to 5
at 43°C °C		-40 to -20
Voltage range	V/Hz	198 - 254 /50
Maximum refrigerant charge R290	g	150

### Flammable Refrigerant:

Unit must only be installed and serviced by authorized personnel (see instructions "Fan-cooled Condensing Units 220-240V for R290", CI.34.C).





### Packing data

Net weight	kg	11.3
Gross weight	kg	13.5
Package height	mm	245
Package width	mm	400
Package depth	mm	530

### Dimensions

Height (H)	mm	198
Width (W)	mm	267
Depth (D)	mm	410
Distance (a)	mm	310
Suction connecton	I.D. mm	6.2
Liquid connection	I.D. mm	6.5
Process connecton	I.D. mm	6.2

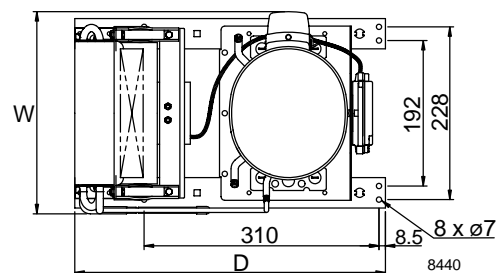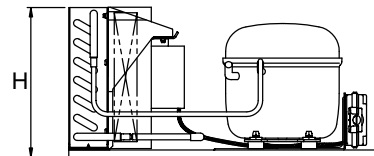

drawing shows **N0** version

