

# NL9CNK

## LBP/MBP Condensing Unit


### R290 (Propane)

### 220-240V 50Hz

#### Data Sheet

#### General

|                                |            |               |
|--------------------------------|------------|---------------|
| <b>Condensing unit</b>         |            | <b>NL9CNK</b> |
| Version                        | Size       | Code number   |
| <b>N0</b> - for capillary tube | <b>BG2</b> | 114F2506      |

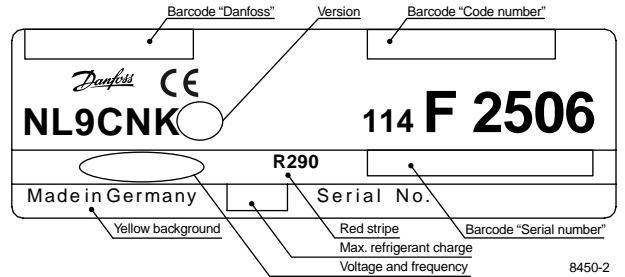

#### Application

|  |            |               |
|--|------------|---------------|
| Application                              |            | LBP/MBP       |
| Evaporating temperature range at 32°C °C |            | -40 to 0      |
|  | at 43°C °C | -40 to -15    |
| Voltage range                            | V/Hz       | 198 - 254 /50 |
| Maximum refrigerant charge R290          | g          | 150           |

#### Flammable Refrigerant:

Unit must only be installed and serviced by authorized personnel (see instructions "Fan-cooled Condensing Units 220-240V for R290", CI.34.C).





#### Packing data

|                |    |     |
|----------------|----|-----|
| Net weight     | kg | 18  |
| Gross weight   | kg | 19  |
| Package height | mm | 245 |
| Package width  | mm | 400 |
| Package depth  | mm | 530 |

#### Dimensions

|                   |         |     |
|-------------------|---------|-----|
| Height (H)        | mm      | 225 |
| Width (W)         | mm      | 298 |
| Depth (D)         | mm      | 432 |
| Distance (a)      | mm      | 310 |
| Suction connecton | I.D. mm | 6.2 |
| Liquid connection | I.D. mm | 6.5 |
| Process connecton | I.D. mm | 6.2 |

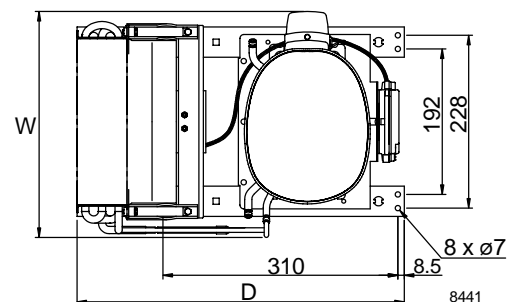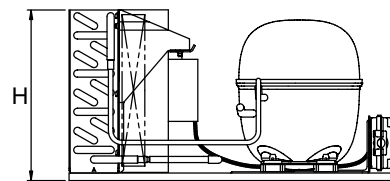

drawing shows **N0** version

