
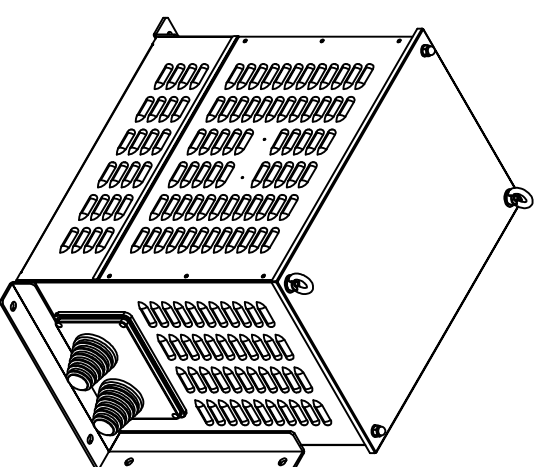
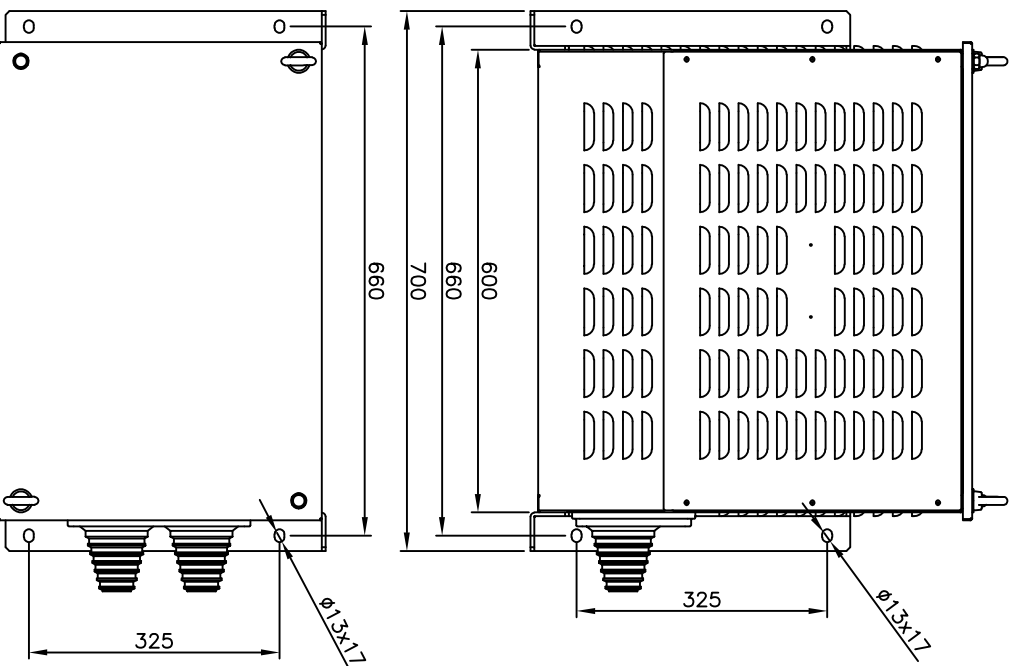


additional informations:
 filter colour : RAL7001
 filter weight : 67,5kg

label:

VLT MCC 102 du/dt FILTER		Danfoss A/S, Ø430 Nordsjælland, Denmark
www.danfoss.com		
TTC: MCC102A480TME23B		SAN: 000170-206
P/N: 130B2850		3x380-690V /-50/60Hz (max 100Hz)
3x480A@40V / 4x3A@500V		344A@600V 290A@960V
NEMA 11P23 Tamb: 45 C/113 F		
130B2850000170-206		
Use only with a type 1 or type 2 SPD overvoltage control device		
E 216622	B 0908115.2	FA-Nr.: 0000000
Ind Contact: H01	See manual for	UL-requirements
UL	EN 61558	CE

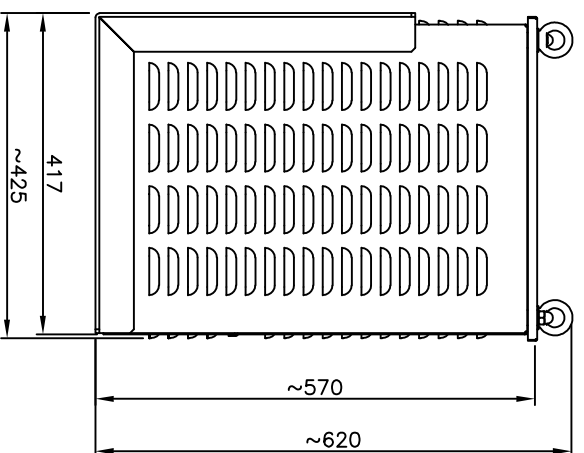

f.19.05.16 Schr./File. type/label updated: Dantross Postadress included
 e.26.11.14 Schr./File. type/label updated
 d.10.04.13 Schr./Kor. type/label updated
 c.25.03.13 Schr./Kor. type/label updated
 b.02.07.10 KOR/BRE approval added
 a.12.01.10 KOR/BRE part-no. added

Dimensions	toleranced	according to	ISO 2768-m		
Tolerance class	0,5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400
m (middle)	±0,1	±0,1	±0,2	±0,3	±0,5

drawn	18.11.09	Kornau	Kornau	scale	1:5
checked	18.11.09	Bremer	Bremer	format	A4
date				DIN ISO	5456
name					
signature					

Dimensions B 0908115.2
 du/dt filter 443A – IP23

order number	130B2850	drawing number	Z790911021	modi.	f	sheet	1/1
Please observe protection clause to ISO 16016							