
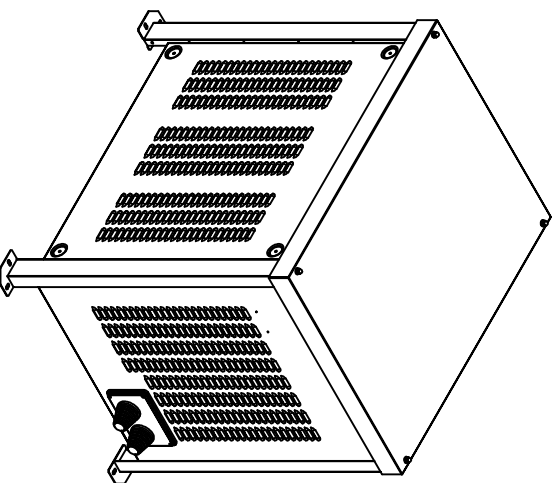
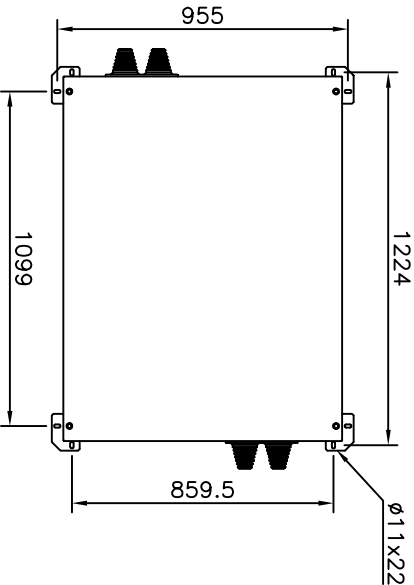


additional informations:  
 filter colour : RAL5008 / R9006  
 filter weight : 425kg

label:

**VT** MOC 101 sine wave FILTER  
 www.danfoss.com  
 Danfoss A/S, 8250 Nordborg, Denmark  
 TAC: MOC101AS107M23AB P/N: 15083168 S/N: 000198-175  
 P/N: 15083168 S/N: 000198-175  
 3x 500-500V / 500Hz (max. 100Hz)  
 3x 470µF/50Hz 450V/50Hz 350V/100Hz  
 MESH 1/125 1mm 45°C/1.1°  
 \*110B31380101.09-175\*  
 Use only with 8 poles 1 or 2 pole 2 STD overvoltage control device  
 E 10010702 P/N: 000000  
 500V AC 50/60Hz  
 EN 61898 CE

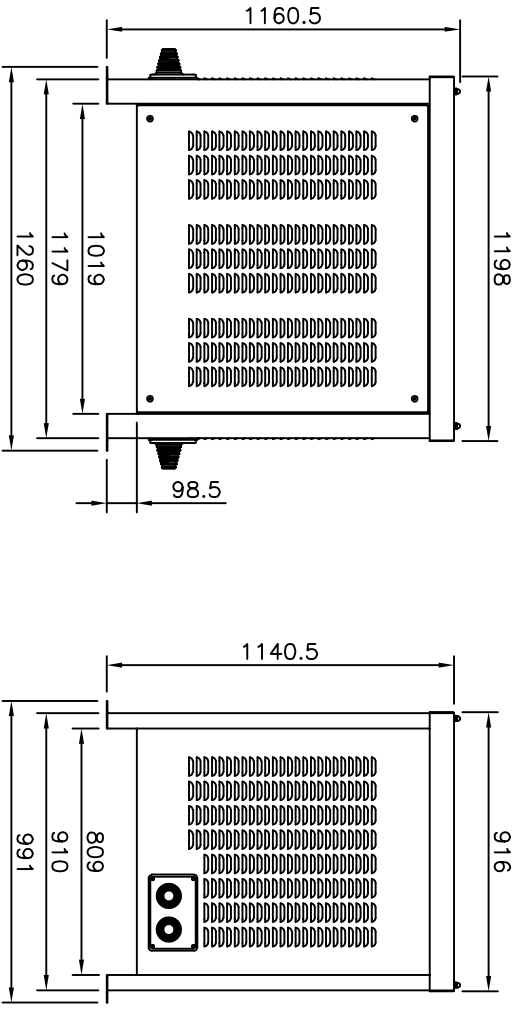

e 29.04.16	Schr./Fie.	typelabel updated, Danfoss Postaddress included
d 05.11.14	Schr./Fie.	typelabel updated
c 08.04.13	Schr./ Kor.	typelabel updated
b 11.03.13	Schr./ Kor.	typelabel updated
a 30.09.10	KOR/Lauer	approval added
date	name	amendment

Dimensions toleranced according to ISO 2768-m						
Tolerance class	0.5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400	from 400 to 1000
m (middle)	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8

drawn	01.06.10	Korrau	Korrau	scale	1:20
checked	01.06.10	Bremer	Bremer	format	A4
date		name	signature		

DIN ISO 5456  
  
 all dimensions mm

Dimensions B 1001076.2  
 sine-wave filter 500V 510A – IP23

order number 130B3189  
 drawing number Z791004030  
 Please observe protection clause to ISO 16016