
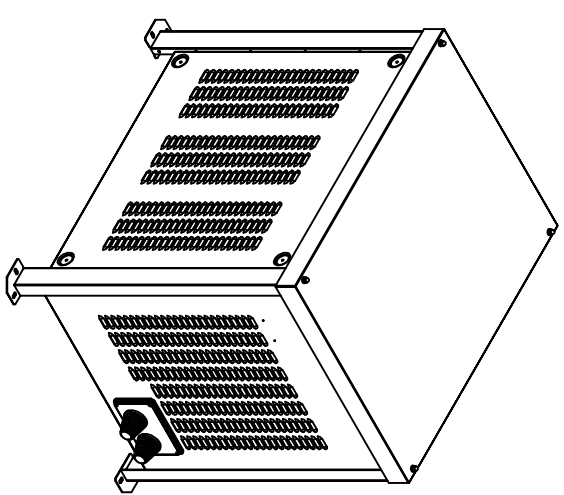
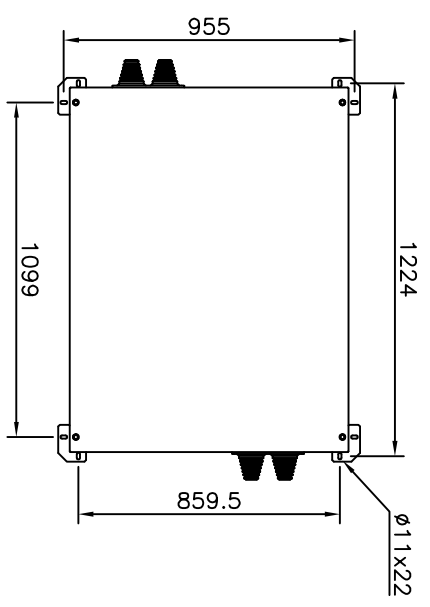
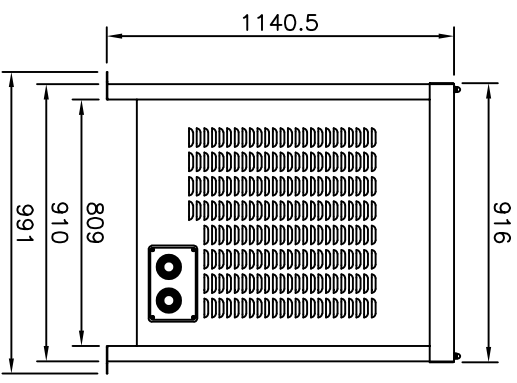
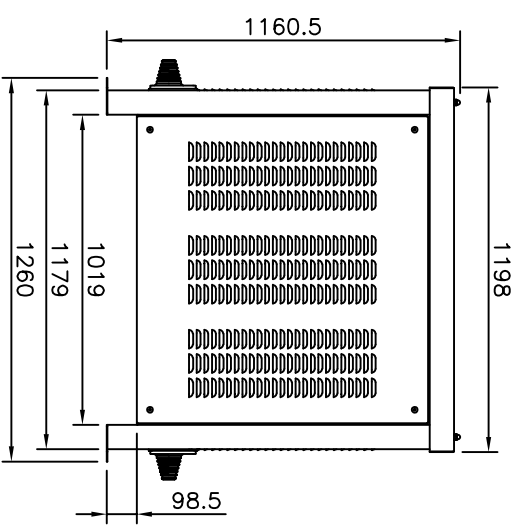


additional informations:
 filter colour : RAL5008 / R9006
 filter weight : 570kg

label:

 VLT MOC 101 sine wave FILTER www.danfoss.com		Danfoss A/S 8430 Vording, Denmark MADE IN GERMANY L=150µH C=318µF R=24KΩ Winding: 570kg Terminals: 30mm	
T/C: MOC101A86073E23E P/N: 130B3192 S/N: 000193-188 3x380-500V / 50/60Hz (max 100Hz) 3x680A/50Hz 625A/60Hz 496A/100Hz NEMA 17F23 Term. 45°C/113°F *130B3192000169-188* Use only with a type 1 or type 2 S+2 overvoltage control device		B 10010772 FA-Nr.: 000007 ID-Nummernschild EN 61558 CE	



e)02.05.16) Schr./Fie. | typelabel updated; Danfoss Postaddress included
 d)10.11.14) Schr./Fie. | typelabel updated
 c)08.04.13) Schr./Kor. | typelabel updated
 b)11.03.13) Schr./Kor. | typelabel updated
 a)30.09.10) KOR/Lauer | approval added
 date | name | amendment

Dimensions toleranced according to ISO 2768-m						
Tolerance class	0.5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400	from 400 to 1000
m (middle)	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8

drawn	01.06.10	Korrau	Korrau	scale	1:20
checked	01.06.10	Bremer	Bremer	format	A4
date			signature		

Dimensions B 1001077.2
 sine-wave filter 500V 660A – IP23

order number	130B3192	drawing number	Z791004031	modi.	e	sheet	1/1
--------------	----------	----------------	------------	-------	---	-------	-----

Please observe protection clause to ISO 16016