
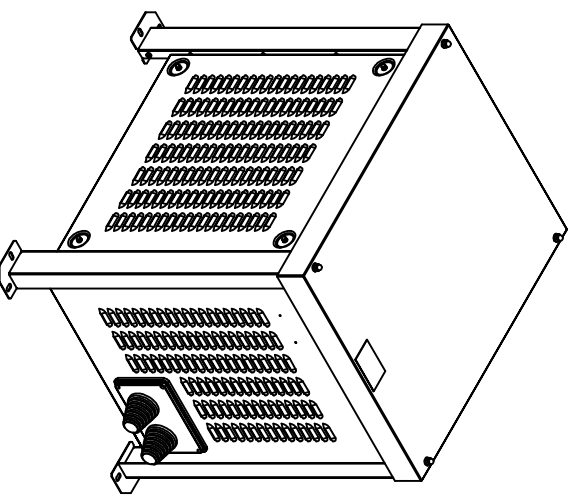
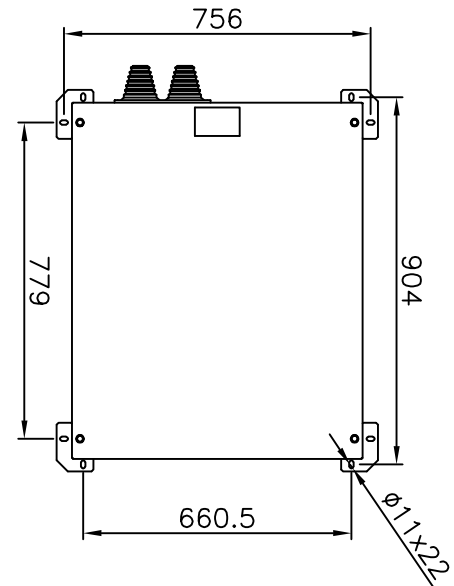
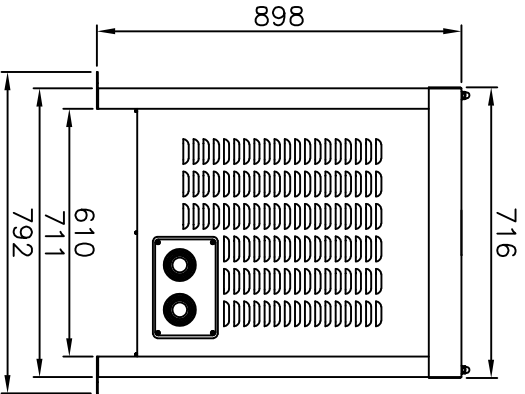
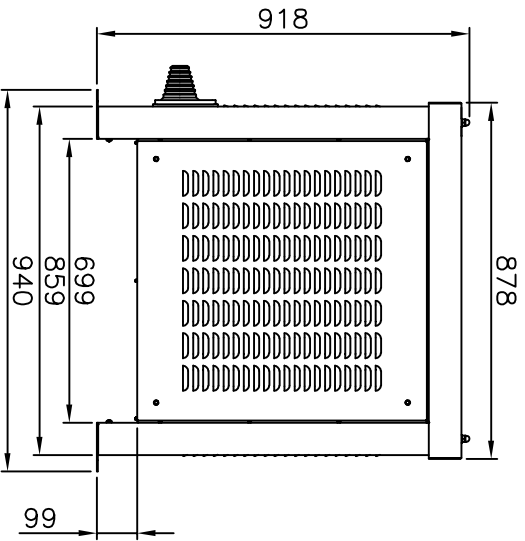


additional informations:
 filter colour : RAL5008 / R9006
 filter weight : 270kg

label:

VLT MCC 101 sine wave FILTER www.danfoss.com		James & Sons Maschinenbau MÄDLE IN GERMANY L-7503H Str. 10 39105 Grottel NEMK 01223 Telp. +49(0)13191 Fax +49(0)13191387 *13100124000103-180* Usage of valve allowed for Mod. 2 SPD 01/06/10/06 control 0591/02	
TFC MCC101 A1577E2B5 P/N 130B4124 39105 Grottel NEMK 01223 Telp. +49(0)13191 Fax +49(0)13191387	S/N: 0001004188 24V @ 100Hz	EN 100052-2 See manual for UL requirements	F-7503H Str. 10 39105 Grottel NEMK 01223 Telp. +49(0)13191 Fax +49(0)13191387 *13100124000103-180* Usage of valve allowed for Mod. 2 SPD 01/06/10/06 control 0591/02
E1100052-2 See manual for UL requirements		F-7503H Str. 10 39105 Grottel NEMK 01223 Telp. +49(0)13191 Fax +49(0)13191387	
EN 16159 			



e 08.05.16	Schr./Fie.	typelabel updated.	Danfoss	Postaddress included
d 17.11.14	Schr./Fie.	typelabel updated		
c 10.04.13	Schr./Kor.	typelabel updated		
b 11.03.13	Schr./Kor.	typelabel updated		
a 01.10.10	KOR/Lauer	approval added		
date	name	amendment		

Dimensions toleranced according to ISO 2768-m						
Tolerance class	0,5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400	from 400 to 1000
m (middle)	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8

drawn	01.06.10	Kornau	Kornau	scale	1:1.5
checked	01.06.10	Bremer	Bremer	format	A4
date		name	signature		

Dimensions B 1002054.2
 sine-wave filter 690V 165A – IP23

order number	130B4124	drawing number	Z791004038	modi.	e	sheet	1/1
Please observe protection clause to ISO 16016							

1 2 3 4 5 6 7 8