
 

 

 
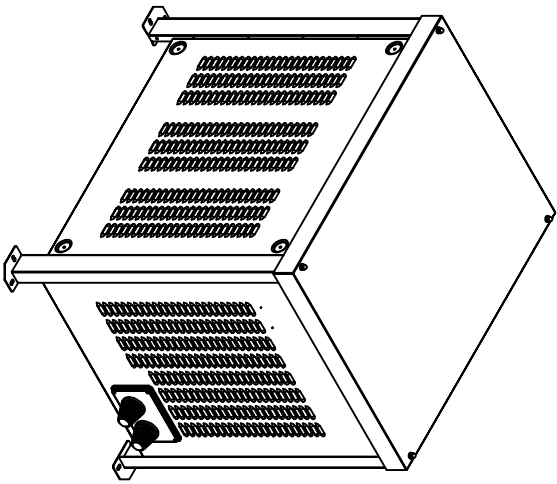
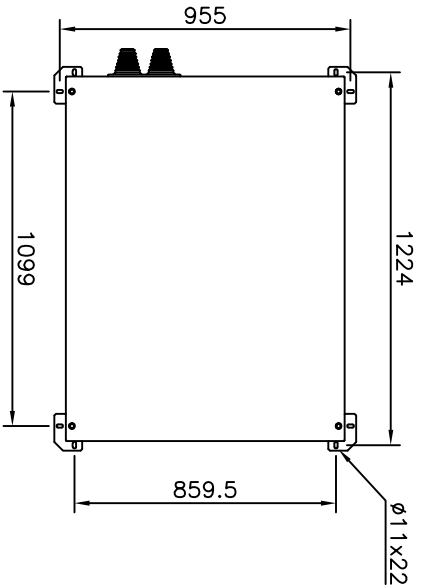
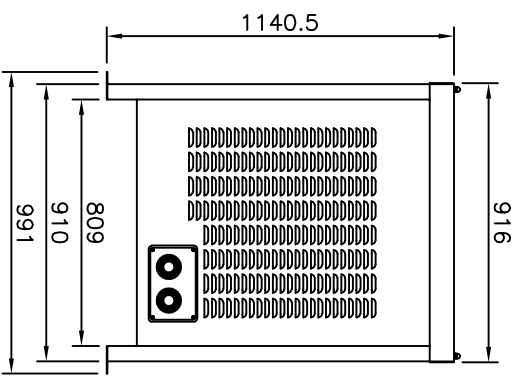
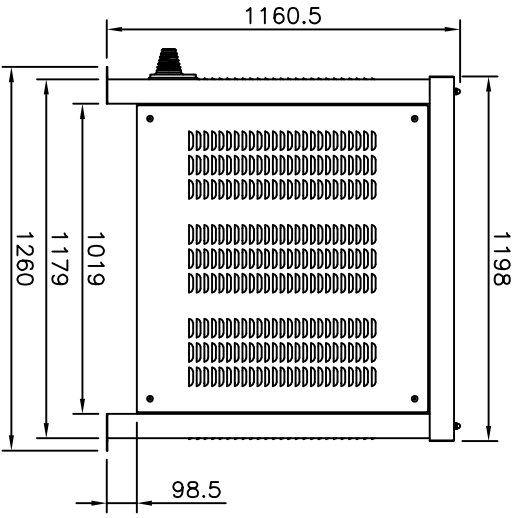


additional informations:
 filter colour : RAL5008 / R9006
 filter weight : 673kg

label:

| | | | |
|---|---|--|---|
|  | | MCC 101 sine wave FILTER Danfoss A/S, B&B Building, Denmark www.danfoss.com | |
| TLC MCC101A350/TL238 | PM 13084151 | SN: 0001661386 | MADE IN DENMARK |
| 3x 55x540V - 50/60Hz (max. 100Hz) | 3x 55x540V - 50/60Hz | 270A @104Hz | L=450mm C=156mm P=151mm Weight: 673kg Type: 101 Terminal: 20mm |
|  | | *130841510001661386 Use only with a 100V - 1000V, 50/60Hz, 3-phase supply device. For more information see manual for MCC101 | |
|  |  |  |  |



| | | |
|------------|------------|---|
| e 09.05.16 | Schr./Fle. | typelabel updated, Danfoss Postaddress included |
| d 17.11.14 | Schr./Fle. | typelabel updated |
| c 11.03.13 | Schr./Kor. | typelabel updated |
| b 11.03.13 | Schr./Kor. | typelabel updated |
| a 01.10.10 | KOR/ Lauer | approval added |
| date | name | amendment |

Dimensions toleranced according to ISO 2768-m

| Tolerance class | 0.5 to 3 | from 3 to 6 | from 6 to 30 | from 30 to 120 | from 120 to 400 | from 400 to 1000 |
|-----------------|----------|-------------|--------------|----------------|-----------------|------------------|
| m (middle) | ±0.1 | ±0.1 | ±0.2 | ±0.3 | ±0.5 | ±0.8 |

| | | | | | |
|---------|----------|--------|-----------|--------|------|
| drawn | 01.06.10 | Korrau | Korrau | scale | 1:20 |
| checked | 01.06.10 | Bremer | Bremer | format | A4 |
| date | | name | signature | | |

Dimensions B 1002056.2
 sine-wave filter 690V 360A – IP23

| | | | | | | | |
|---|----------|----------------|------------|-------|---|-------|-----|
| order number | 130B4151 | drawing number | Z791004040 | modi. | e | sheet | 1/1 |
| Please observe protection clause to ISO 16016 | | | | | | | |