
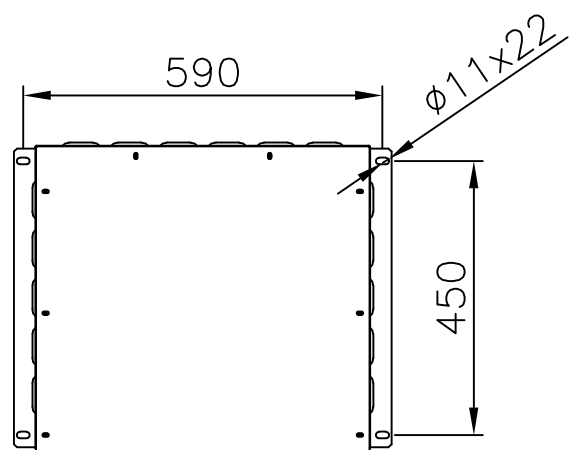
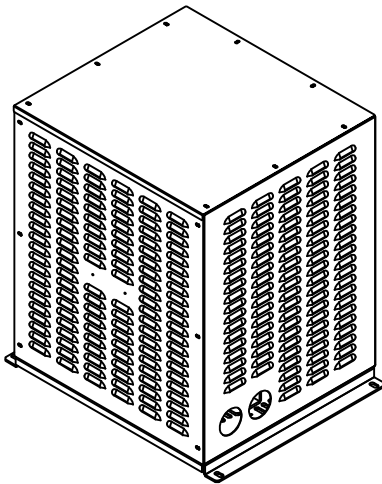
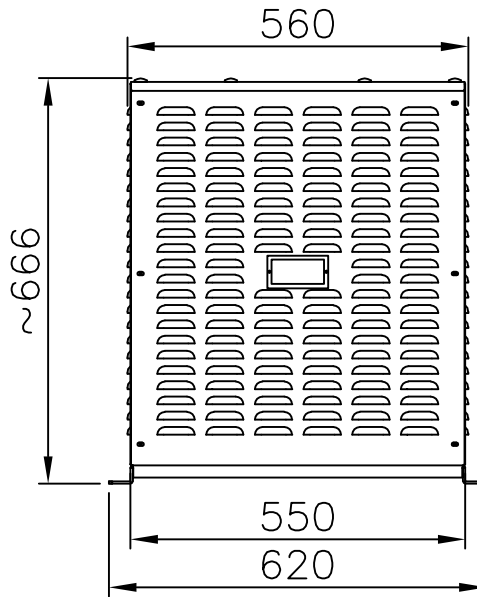
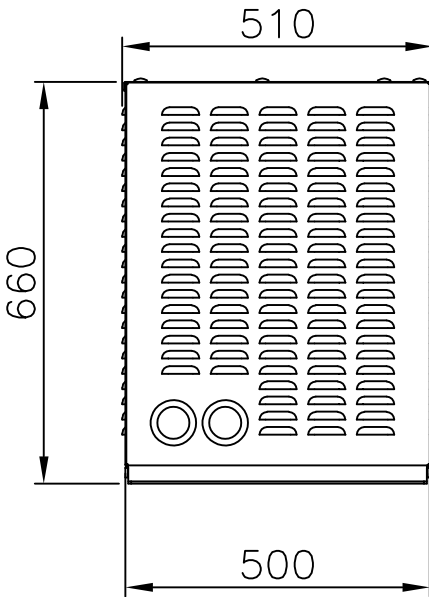


additional informations:

filter colour : RAL7001
 filter weight : 229kg

label:

VLT[®] MCC 101 sine wave FILTER www.danfoss.com		Danfoss A/S, 6430 Nordborg, Denmark	
T/C: MCC101A260T3L23B	S/N: 000167-176	MADE IN GERMANY	
PN: 130B9027	L=340µH	Cy=75µF	
3x 380-500V - 50/60Hz (max.100Hz)	fs=3kHz	Ploss: 850W	
3x 260A@50Hz 246A@60Hz 195@100Hz	Weight: 229kg	Tightening torque terminal: 18Nm	
NEMA 1/IP23 Tamb. 45°C/113°F			
130B9027000167-176			
Use only with a type 1 or type 2 SPD overvoltage control device			
E 219022 Ind. Cont. Eq. 1HD1	B 1001074.1 FA-Nr.: 000000 See manual for UL-requirements	EN 61558	

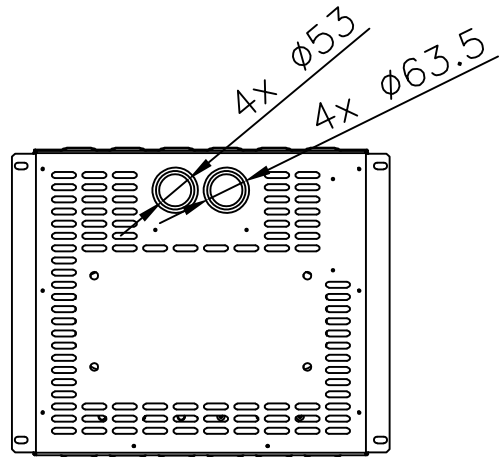

	date	name	amendment
c	27.04.16	Schr./Fle.	typelabel updated Danfoss Postadress included
b	21.06.15	Schr./Fle.	typelabel updated
a	05.11.14	Schr./Fle.	typelabel updated

drawn	13.12.13	Kornau	Kornau	scale	1:10
checked	13.12.13	Denecke	Denecke	formate	A4
	date	name	signature		

Dimensions B 1001074.1
 sine-wave filter 500V 260A – IP23s

	order number	drawing number	modi.	sheet
	130B9027	Z791312009	c	1/1
all dimensions mm		Please observe protection clause to ISO 16016		