
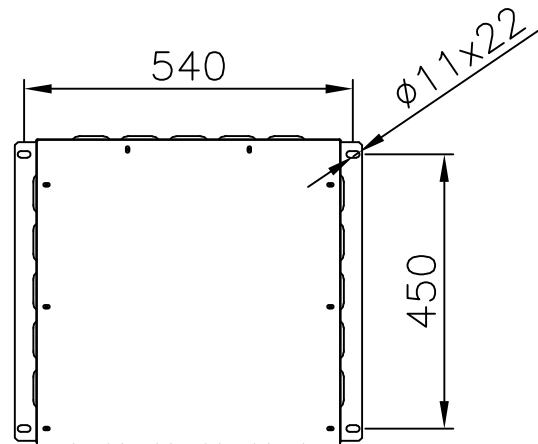
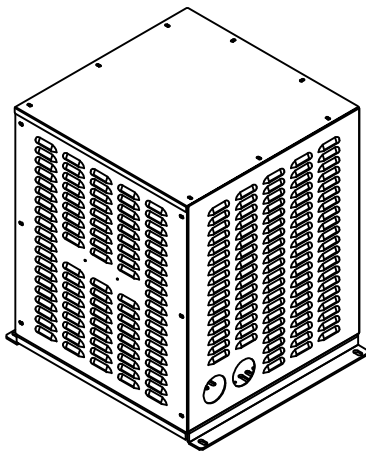
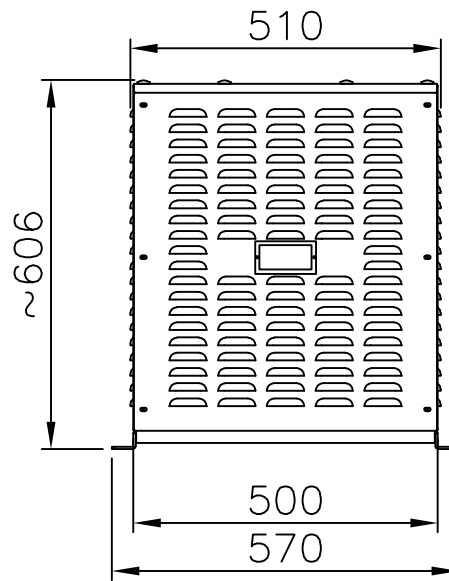
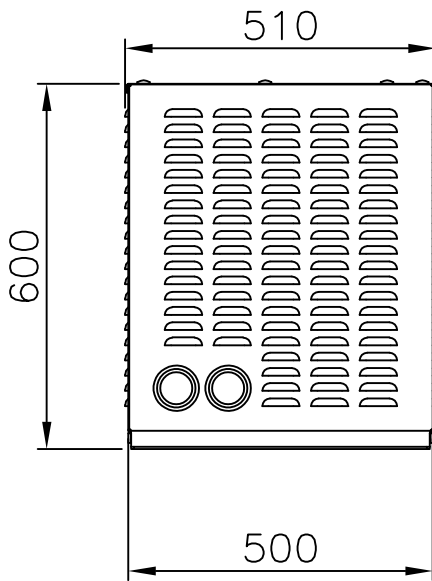


additional informations:

filter colour : RAL7001  
 filter weight : 136kg

label:

<b>VLT</b> MCC 101 sine wave FILTER		Danfoss A/S, 6430 Nordborg, Denmark	
www.danfoss.com			
TIC: MCC101A76K7TL23B	PN: 130B9028	SN: 000168-186	MADE IN GERMANY
3x 525-690V - 50/60Hz (max. 100Hz)	L=1,4mH	Cj=33µF	
3x 76A@60Hz 72A@60Hz 57A@100Hz	fsw=3kHz	Ploss=475W	
NEMA 1IP23 Tamb. 45°C/113°F	Weight: 136kg	Tightening torque	
*130B9028000168-186*		terminal: 6,0-12,0Nm	only CU
Use only with a type 1 or type 2 SPD overvoltage control device			
E 219022 Ind. Cont. Eq. 1HD1 Umace600V	B 1002052.1 See manual for UL-requirements	FA-Nr. 000000	EN 61558

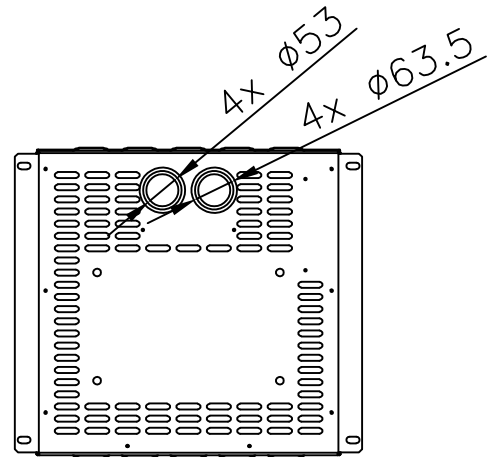

	date	name	amendment
d	08.05.16	Schr./Fle.	typelabel updated, Danfoss Postaddress included
c	21.06.15	Schr./Fle.	typelabel updated
b	10.11.14	Schr./Fle.	typelabel updated
a	23.12.13	Heu./Schr.	typelabel updated

drawn	date	name	signature	scale
	27.08.13	Kornau		1:10
checked	date	name	signature	formate
	27.08.13	Denecke		A4

Dimensions B 1002052.1  
 sine-wave filter 690V 76A - IP23s

DIN ISO 5456  
  
 all dimensions mm

order number	drawing number	modi.	sheet
130B9028	Z791308010	d	1/1

Please observe protection clause to ISO 16016