




Side view, right

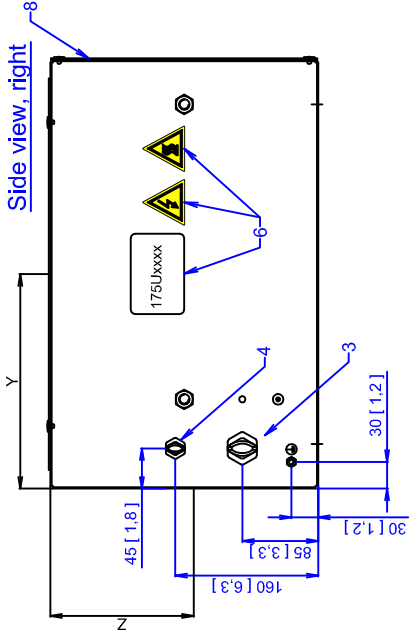


Front view

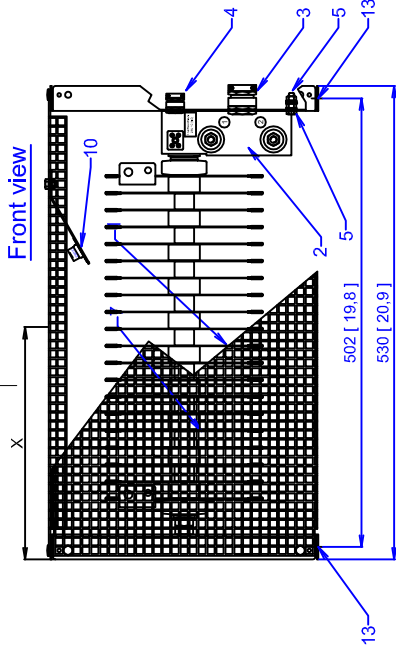


Side view, left

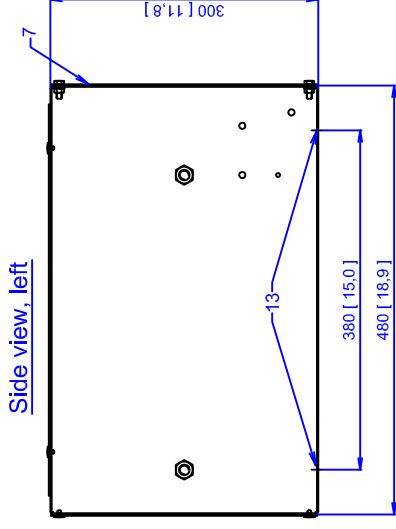

Detail view

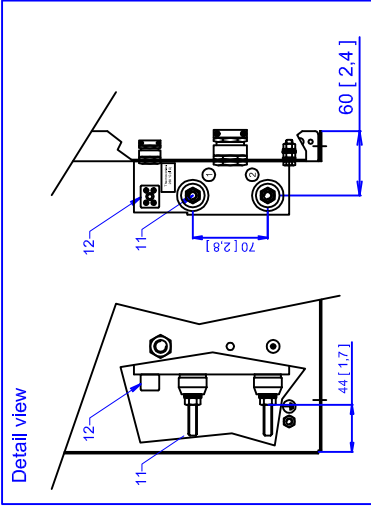

Top view

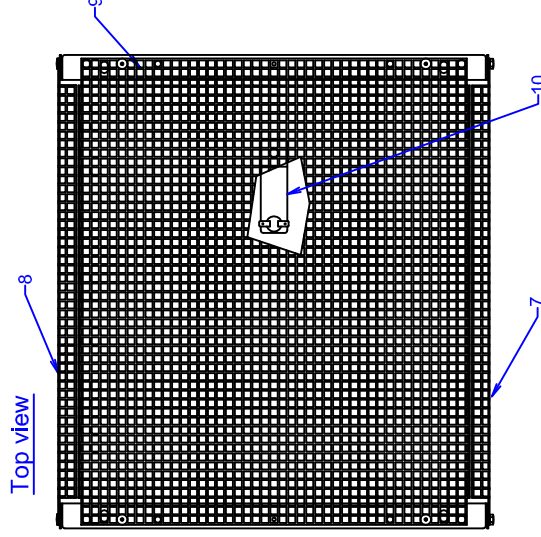

Name Plate



DECLARATION

1. Resistor
2. Terminal board, see detail view
3. Cable gland for load cables
4. Cable gland M16 thermo contact cable
5. Eathing bolt M6
6. Name plate / Warning signs
7. Front cover IP20
8. Rear cover IP20
9. Top cover IP20
10. Thermocontact 260 °C (NC)
11. Load connection, 2x bolt M8
12. Auxiliary connection for thermo contact, porcelain clamp 2,5²
13. 4x fixing hole Ø 9mm

CABINET TYPE: CM15

Danfoss code	Typecode	Ohm	cable gland type for load cables (3)	Weight [kg]	Center of mass [mm]		
					X	Y	Z
175U3067	MCE101C9R10P9K00E20BAW	9,1	M40	21	255	260	155
175U3079	MCE101C4R70P9K00E20BAW	4,7	M40	21	255	260	155
175U3200	MCE101C27R0P10K0E20BAW	27,0	M25	22	255	260	155
175U3203	MCE101C19R0P10K0E20BAW	19,0	M25	22	255	260	155
175U3231	MCE101C5R80P7K0E20BAW	5,5	M32	19	255	260	155
175U3232	MCE101C11R0P7K0E20BAW	11,0	M25	19	255	260	155
175U3233	MCE101C5R70P8K00E20BAW	5,7	M25	19	255	260	155
175U3234	MCE101C5R70P8K00E20BAW	5,7	M25	20	255	260	155
175U3235	MCE101C3R50P9K00E20BAW	3,5	M25	21	255	260	155
175U3237	MCE101C28R0P6K00E20BAW	28,0	M25	19	255	260	155
175U3238	MCE101C22R0P8K00E20BAW	22,0	M25	20	255	260	155
175U3239	MCE101C38R0P6K00E20BAW	38,0	M25	19	255	260	155
175U3240	MCE101C31R0P8K00E20BAW	31,0	M25	20	255	260	155
175U3242	MCE101C52R0P8K00E20BAW	52,0	M25	19	255	260	155
175U3243	MCE101C42R0P8K00E20BAW	42,0	M25	20	255	260	155
175U3244	MCE101C31R0P10K0E20BAW	31,0	M25	22	255	260	155
175U3245	MCE101C7R00P7K00E20BAW	7,0	M32	20	255	260	155



Danfoss A/S
Power Electronics Division
Ulsmes 1, 6300 Grøsten
Denmark

MCE101 Brake resistor
xxR±10% IP20
175C0607

Material: Cabinet material
Zinc plated steel, without coating.
Path:

Weight (g)	-	Date	14.03.2012	Creator:	F. Bülle	H. Hansen	Scale	1:1	
Tolerance:				File:	917CM15_02.dwg				
No.:	02	Last Revision:	13/637	Rev Date:	11.12.2013	F. Bülle	Paper size:	A3	
Drawing No.:							Sheet:		1 of 1
							917CM15		