

A

B

C

D

E

F

A


B

C

D

E

F

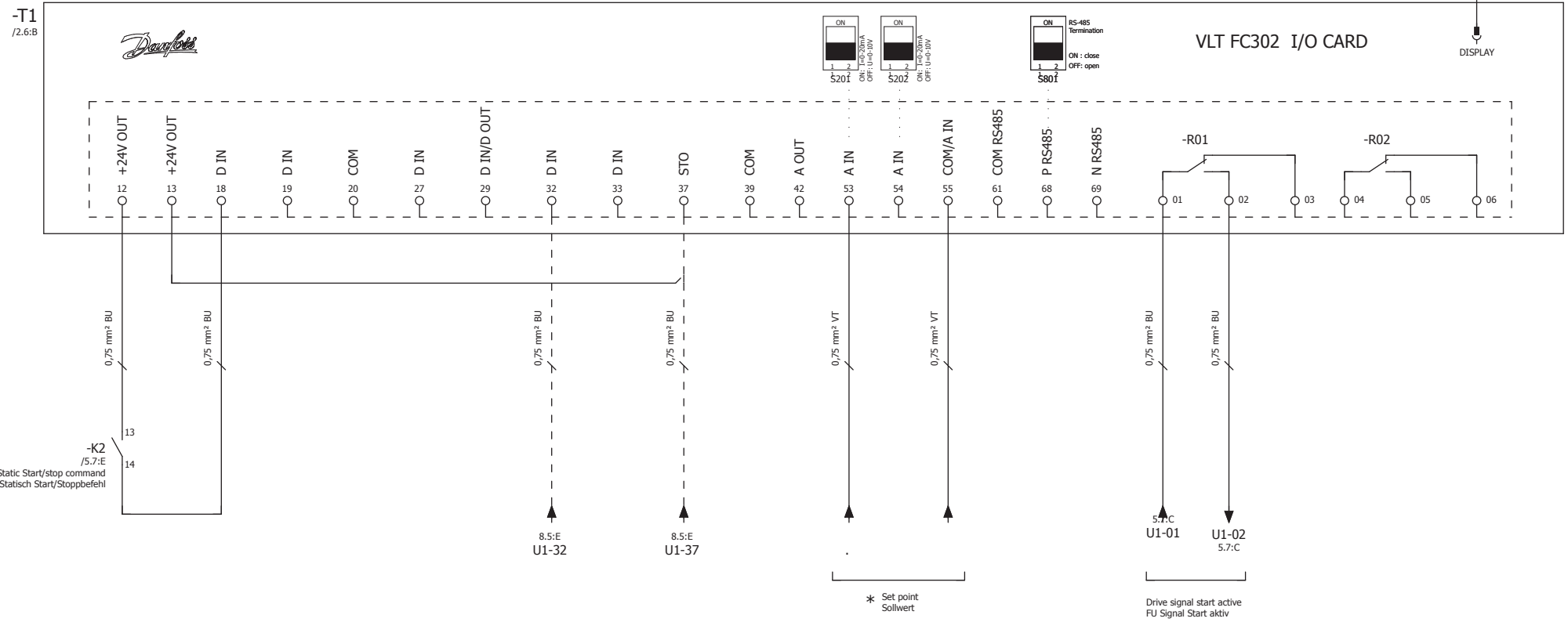

Parameter list

Parameter	Description Beschreibung	Value Wert
5-40	Ready	2
5-12	Without function	0

\* Current input, 0-20mA and 4-20mA  
Stromeingang, 0-20 mA und 4-20 mA  
Voltage input, -10 - +10 V DC  
Spannungseingang -10 - +10 V DC

Modification	Date	Name	Contr.	Date	9/30/2013
				Ed.	----
				Appr	----
				Contr.	----

Commission  
**132KW VFD Panel**  
Project description  
Contactor+Fuse+Disconnect switch  
Schütz+Sicherung+Trennschalter

Danfoss GmbH  
VLT Drives EMA, Carl-Legien Strasse 8  
63073 Offenbach, Germany



FILE-NAME:  
LOG08300.jpg  
Size 300px x 116px

Page description  
Frequency converter  
Frequenzumrichter

Project Number	----	= FC302
SAP NO		+ N132KW 230V
Manufacturer no		