


-T1  
/2.5:B



VLT FC302 I/O CARD



DISPLAY

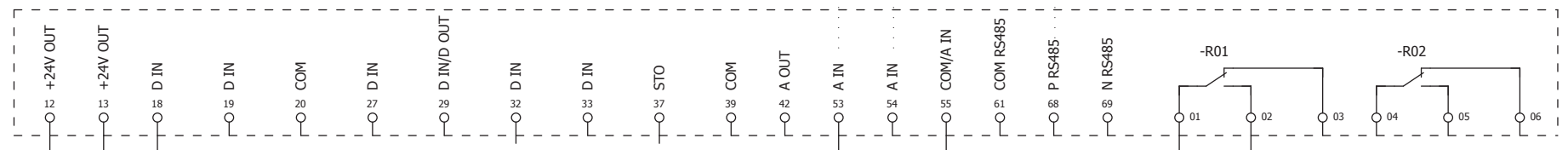

-K2  
/5.7:E  
Static Start/stop command  
Statisch Start/Stoppbefehl

\* Set point Sollwert

Drive signal start active  
FU Signal Start aktiv

Parameter list

Parameter	Description Beschreibung	Value Wert
5-40	Ready	2
5-12	Without function	0

\* Current input, 0-20mA and 4-20mA  
Stromeingang, 0-20 mA und 4-20 mA  
Voltage input, -10 - +10 V DC  
Spannungseingang -10 - +10 V DC

Modification	Date	Name	Contr.

Commission	9/30/2013	315KW VFD Panel
Ed.	----	Project description
Appr	----	Contactor+Fuse+Disconnect switch
Contr.	----	Schütz+Sicherung+Trennschalter

Danfoss GmbH  
VLT Drives EMA, Carl-Legien Strasse 8  
63073 Offenbach, Germany



FILE-NAME:  
LOG08300.jpg  
Size 300px x 116px

Page description  
Frequency converter  
Frequenzumrichter

Project Number	----
SAP NO	

= FC302
+ P315KW 230V
Manufacturer no