


 


-P1
Display
Anzeige

DISPLAY

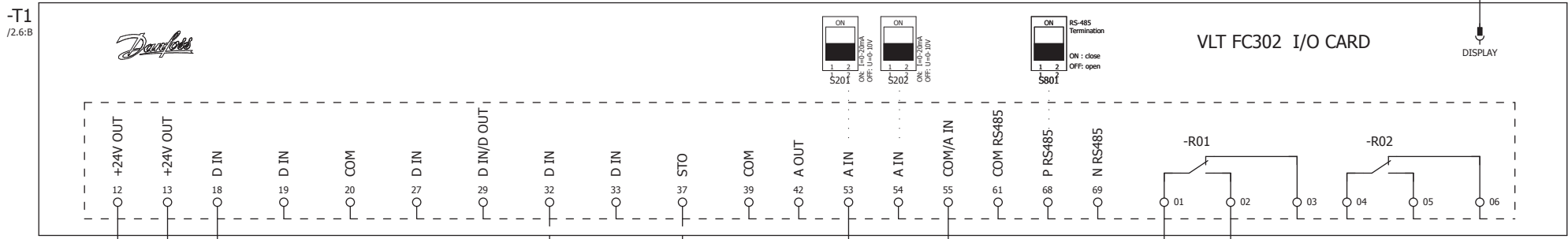

-T1
/2.6:B



-K2
/5.7:E
Static Start/stop command
Statisch Start/Stopfbefehl

* Set point
Sollwert

Drive signal start active
FU Signal Start aktiv

Parameter list

Parameter	Description Beschreibung	Value Wert
5-40	Ready	2
5-12	Without function	0

* Current input, 0-20mA and 4-20mA
Stromeingang, 0-20 mA und 4-20 mA
Voltage input, -10 - +10 V DC
Spannungseingang -10 - +10 V DC

Modification	Date	Name	Contr.

Commission	9/30/2013
Project description	90KW VFD Panel
Appr	----
Contr.	----

Danfoss GmbH
VLT Drives EMA, Carl-Legien Strasse 8
63073 Offenbach, Germany



FILE-NAME:
LOG08300.jpg
Size 300px x 116px

Page description
Frequency converter
Frequenzumrichter

Project Number	----
SAP NO	-----

= FC302
+ N90KW 230V
Manufacturer no