


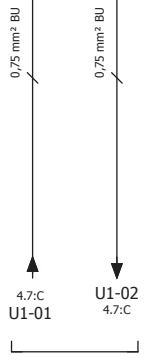
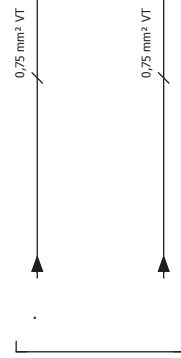


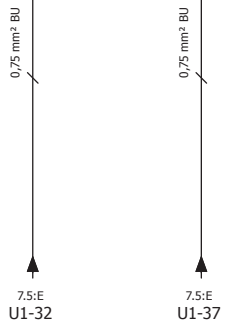

-U1 /2.5:B

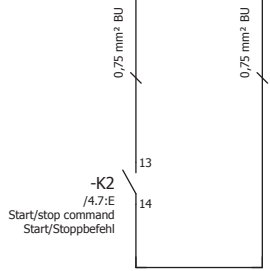

VLT FC302 I/O CARD

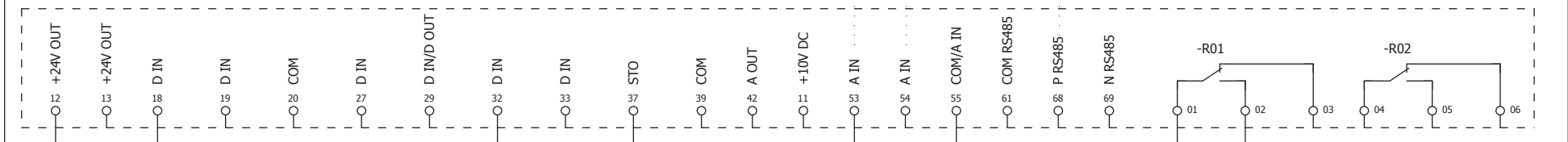

* Set point Sollwert

Drive signal start active [123]
FU Signal Start aktiv [123]

* Current input, 0-20mA and 4-20mA
Stromeingang, 0-20 mA und 4-20 mA
Voltage input, -10 - +10 V DC
Spannungseingang -10 - +10 V DC

Modification	Date	Name	Contr.	KARTHIK

Commission	9/30/2013
Ed.	RAMKUMAR
Appr	FALCO
Contr.	KARTHIK

110KW VFD Panel
Project description
Contactor+Fuse

Danfoss GmbH
VLT Drives EMA, Carl-Legien Strasse 8
63073 Offenbach, Germany



FILE-NAME:
LOG08300.jpg
Size 300px x 116px

Page description
Frequency converter
Frequenzumrichter

Project Number
MC_ - - - -
SAP NO

= FC302
+ N110KW 230V
Manufacturer no