
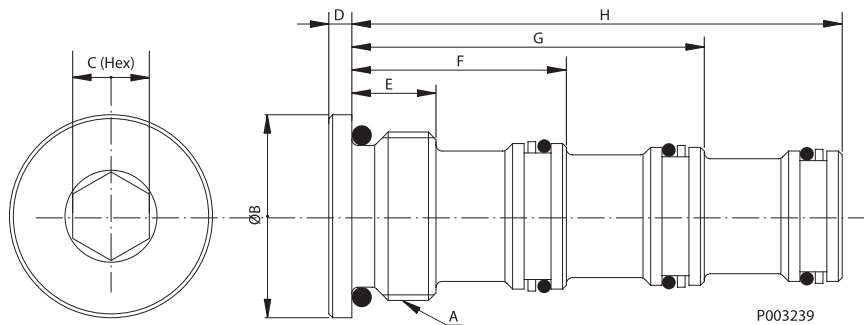


**PLUGS FOR NCS CAVITIES**

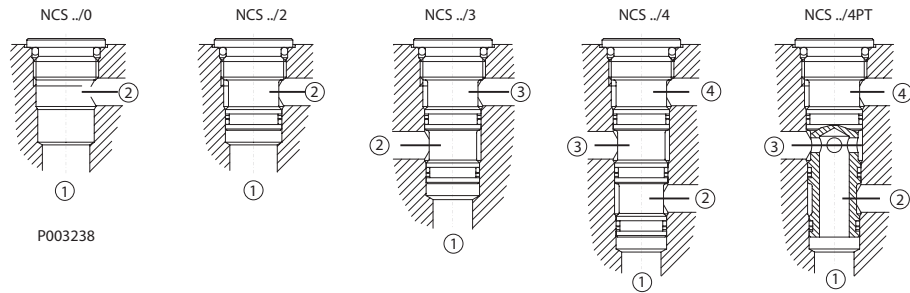

**Dimensions**

Type	Dimensions-mm								Order number for plug complete	Weight of plug complete-kg [lbs.]
	A	B	C	D	E	F	G	H		
NCS 04/0	M18x1.5	22 [0.87]	8	3 [0.12]	10.5 [0.41]	—	—	—	92.00.010.1	0.018 [0.04]
NCS 04/2	M18x1.5	22 [0.87]	8	3 [0.12]	—	24.5 [0.96]	—	—	92.00.009.1	0.035 [0.08]
NCS 04/3	M18x1.5	22 [0.87]	8	3 [0.12]	—	—	39.5 [1.56]	—	92.00.008.1	0.057 [0.13]
NCS 04/4	M18x1.5	22 [0.87]	8	3 [0.12]	—	—	—	54.5 [2.15]	92.00.007.1	0.070 [0.15]
NCS 04/4PT	M18x1.5	22 [0.87]	8	3 [0.12]	—	—	—	54.5 [2.15]	92.00.021.1	0.060 [0.13]
NCS 06/0	M22x1.5	26 [1.02]	10	3 [0.12]	11 [0.43]	—	—	—	92.00.006.1	0.032 [0.07]
NCS 06/2	M22x1.5	26 [1.02]	10	3 [0.12]	—	28 [1.10]	—	—	92.00.004.1	0.060 [0.13]
NCS 06/3	M22x1.5	26 [1.02]	10	3 [0.12]	—	—	46 [1.81]	—	92.00.014.1	0.098 [0.22]
NCS 06/4	M22x1.5	26 [1.02]	10	3 [0.12]	—	—	—	64 [2.52]	92.00.013.1	0.120 [0.26]
NCS 06/4PT	M22x1.5	26 [1.02]	10	3 [0.12]	—	—	—	64 [2.52]	92.00.020.1	0.100 [0.22]
NCS 12/0	M33x2	38 [1.50]	12	3 [0.12]	15 [0.59]	—	—	—	92.00.018.1	0.117 [0.26]
NCS 12/2	M33x2	38 [1.50]	12	3 [0.12]	—	38 [1.50]	—	—	92.00.017.1	0.200 [0.44]
NCS 12/3	M33x2	38 [1.50]	12	3 [0.12]	—	—	63 [2.48]	—	92.00.016.1	0.280 [0.62]
NCS 12/4	M33x2	38 [1.50]	12	3 [0.12]	—	—	—	88 [3.46]	92.00.015.1	0.370 [0.81]
NCS 12/4PT	M33x2	38 [1.50]	12	3 [0.12]	—	—	—	88 [3.46]	92.00.022.1	0.310 [0.68]