



OPERATION Install in manifold to restrict fluid flow.

SCHEMATIC









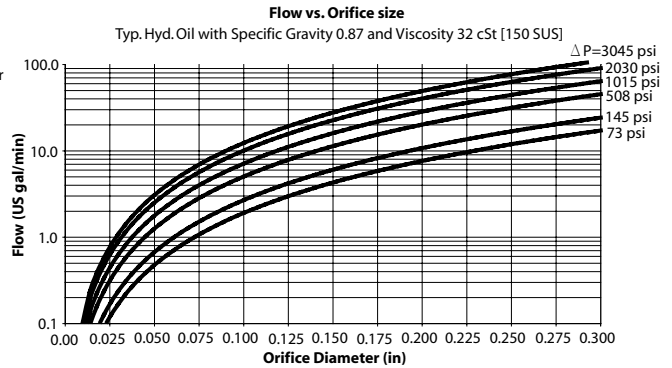


SPECIFICATIONS

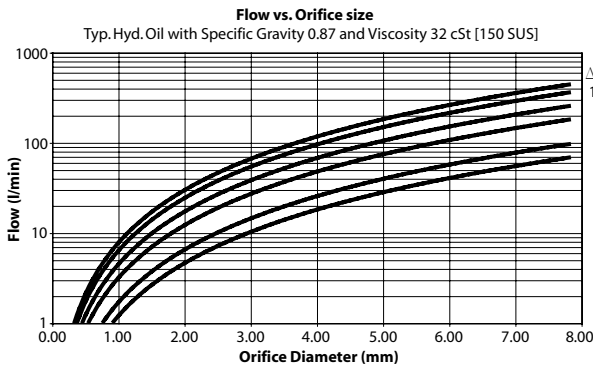

DIMENSIONS

mm [in]

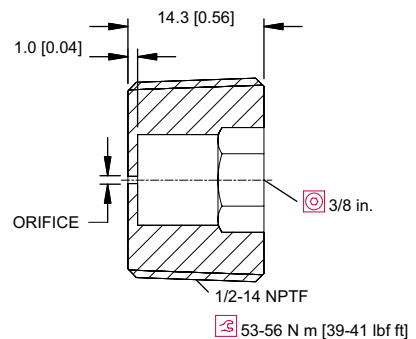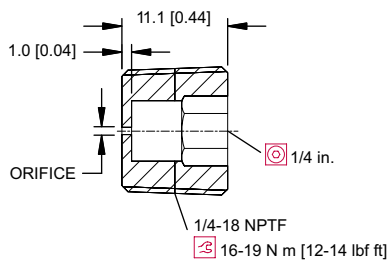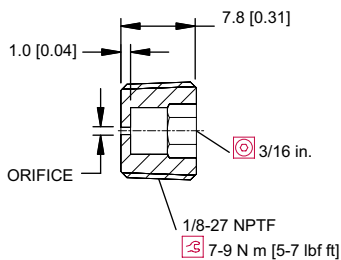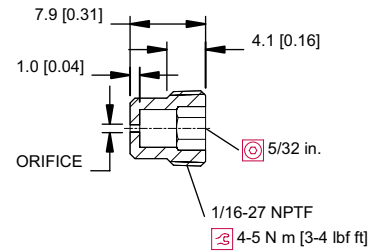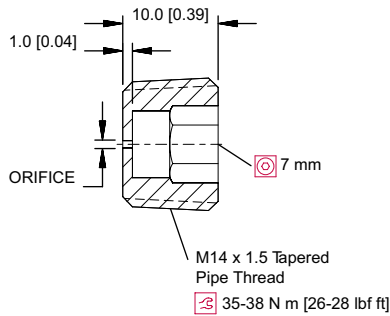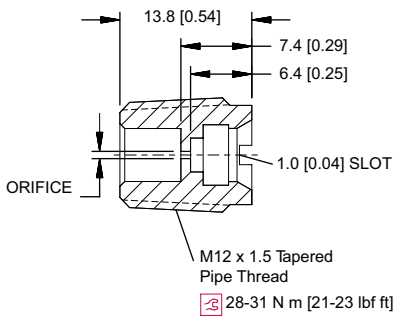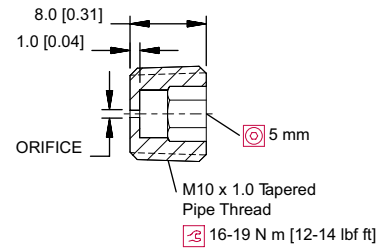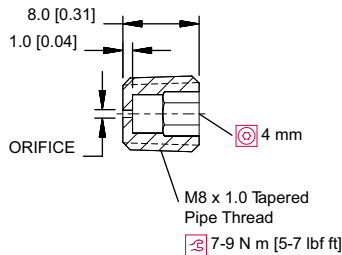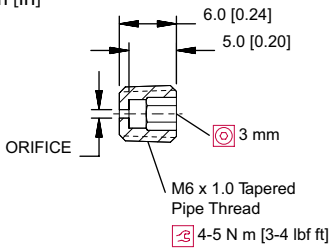

**ORDERING
 INFORMATION**

Orifice Diameter		Orifice Plug Part Number								
		Plug Thread Size								
mm	[in]	1/16-27 NPTF	1/8-27 NP TF	1/4-18 NP TF	1/2-14 NP TF	M6 x 1.0 Ta per e d P ipe Thread	M8 x 1.0 Ta per e d P ipe Thread	M10 x 1.0 Ta per e d P ipe Thread	M12 x 1.5 Ta per e d P ipe Thread	M14 x 1.5 Ta per e d P ipe Thread
None	None			320151	320153	624910	321561	321562	626059	321660
0.33	0.013	11008337				625958				
0.38	0.015	620510				625414				
0.43	0.017								626062	
0.46	0.018									
0.51	0.020	621510	11015116			624898	625190			
0.61	0.024	622417				624904		624478		
0.64	0.025	620634				624862	624838			
0.71	0.028	622846				62486				
0.76	0.030	620296	620299							
0.79	0.031					624855	624857	624308	626133	625266
0.81	0.032	624410								
0.89	0.035	622447				624903	625346	625424		
0.91	0.036	620777				626022				
0.97	0.038	621608								
0.99	0.039					624856	624821			
1.02	0.040	620511								
1.07	0.042	621702				626075				
1.14	0.045	621210								
1.19	0.047	620814	620591				624892	624427		
1.32	0.052	620573				624911	626100			
1.40	0.055	620572								
1.50	0.059					624846	624822	624152		
1.52	0.060	620297								
1.57	0.062	621496								
1.60	0.063					625197	624902	625252		
1.70	0.067					624844				
1.78	0.070	621554				625871	626041			
1.98	0.078	622117								
2.01	0.079					626135	624681	624153		
2.03	0.080									
2.06	0.081									
2.13	0.084									
2.18	0.086	621246								
2.21	0.087						625067			
2.26	0.089									
2.29	0.090					625002				
2.39	0.094		622721			625542		626138		
2.44	0.096	621051		626010						
2.46	0.097						626185			
2.49	0.098									
2.59	0.102						625630			
2.64	0.104									
2.67	0.105			621665						
2.74	0.108							625049		
2.79	0.110						625492			
2.82	0.111									
2.95	0.116	620575								
3.00	0.118							624480		
3.05	0.120									
3.10	0.122									
3.18	0.125		622722				626058	626151		
3.28	0.129									
3.30	0.130									
3.35	0.132						625543			
3.45	0.136									
3.56	0.140		622114						625929	
3.78	0.149	623712								
3.96	0.156									
4.06	0.160			621666						
4.22	0.166									
4.57	0.180		624362							
4.78	0.188				623224					
5.00	0.197									624501
5.16	0.203									
5.61	0.221									
5.84	0.230									625981
6.35	0.250									625068
7.92	0.312									

 
*Contact factory for additional orifice sizes.

P106 018E

OPERATION

Install in manifold to restrict fluid flow.

SCHEMATIC




PERFORMANCE

Refer to Orifice plug sizing chart on page 18.28

DIMENSIONS

mm [in]

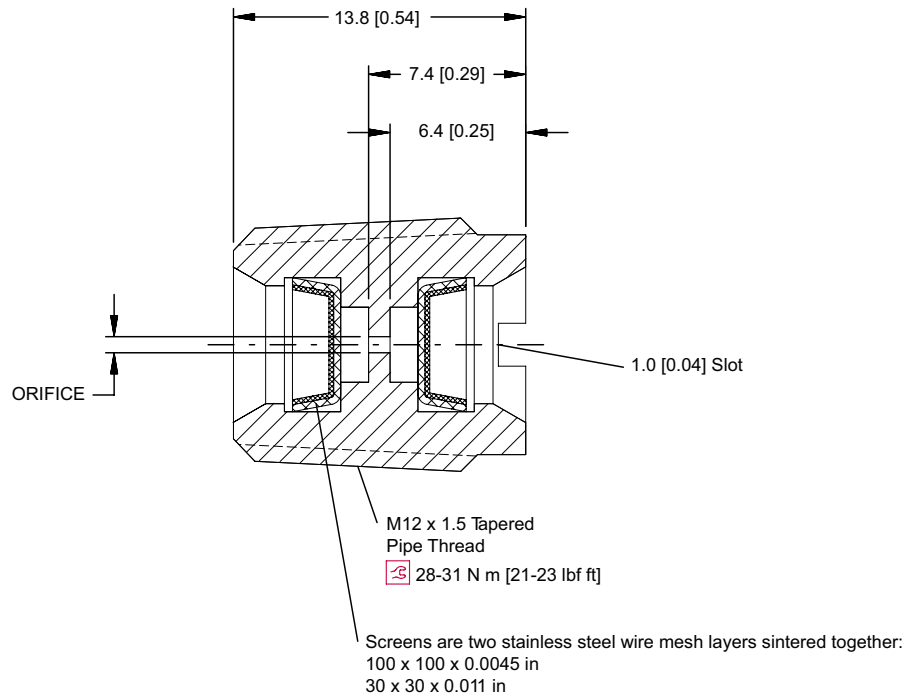

ORDERING INFORMATION

Orifice Diameter		Orifice Plug Part Number
mm	[in]	
0.38	0.015	923231
0.43	0.017	923038
0.46	0.018	923239
0.51	0.020	923061
0.64	0.025	923053
1.19	0.047	11070992
1.91	0.075	923186
3.56	0.140	923112