


OPERATION


This valve is a non-pressure compensated, adjustable flow control valve.

Schematic

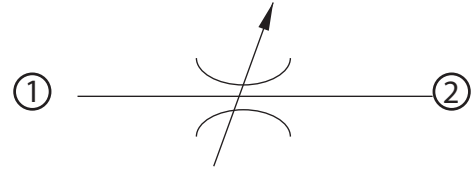

SPECIFICATIONS

Theoretical performance

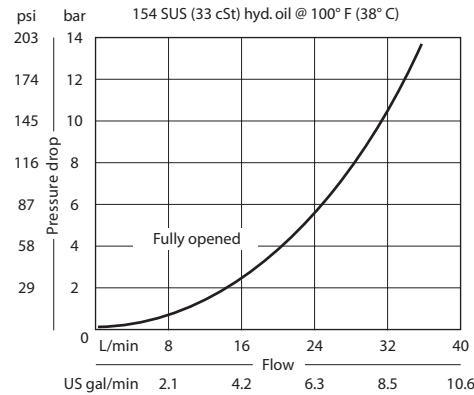


Specifications

Rated pressure	210 bar [3000 psi]
Rated flow at 7 bar [100 psi]	25 l/min [7 US gal/min]
Leakage	6 drops/min @ Rated pressure
Weight	0.07 kg [0.15 lb]
Cavity	SDC08-2


DIMENSIONS

mm in

Cross-sectional view

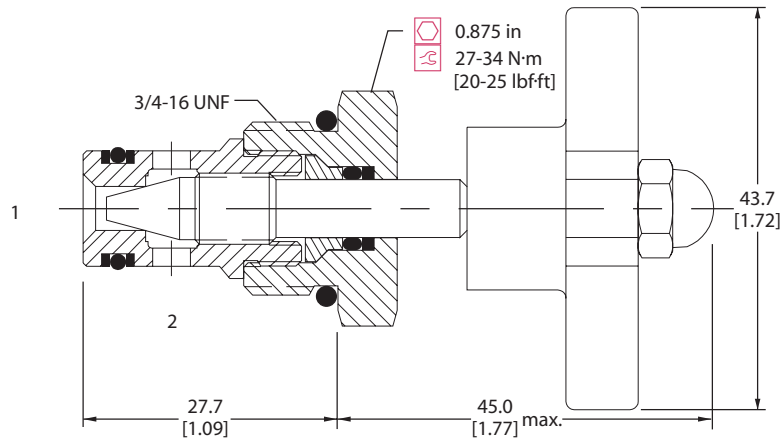

ORDERING INFORMATION

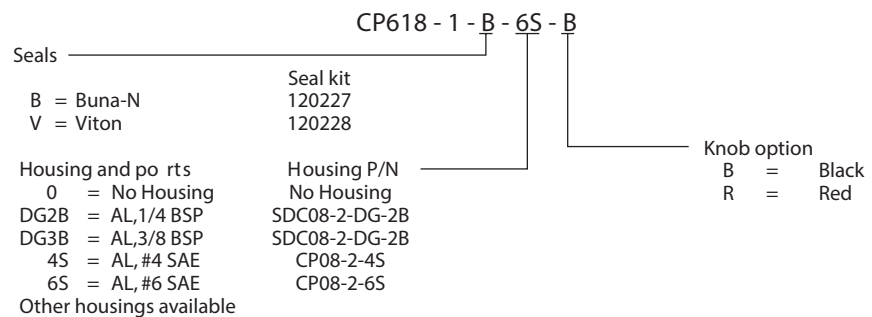

FC - Flow Control Valves
CP618-1