


OPERATION


This is a single counterbalance HIC (on B port) that mounts to OMP/OMR motors with BSP porting.

Schematic

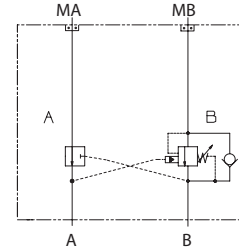

SPECIFICATIONS

Theoretical performance

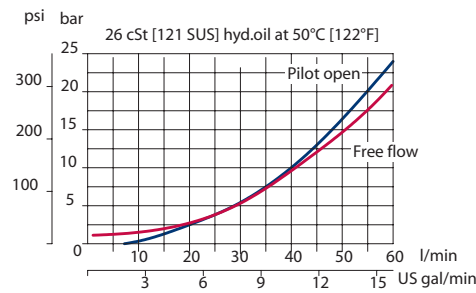


Specifications

Rated pressure	210 bar [3045 psi]
Rated flow at 22 bar [319 psi]	60 l/min [16 US gal/min]
Leakage	6 drops/min @ 70% of crack pressure
Weight	1.43 kg [3.15 lb]
Pilot ratio	3.0:1, 4.5:1, 10.0:1
Cartridge	CB10 HV
Plug	SDC10-V-3S-B1
Service mount kit	11023762
Motor	OMP/OMR

DIMENSIONS


Cross-sectional view

mm [in]

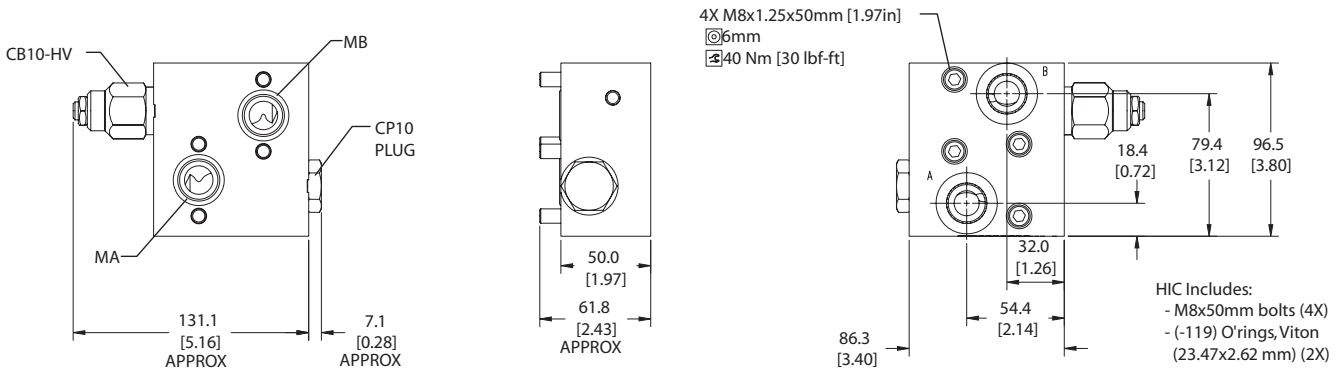

ORDERING INFORMATION

MM-OMP/OMR-00-BCB10-HV-1-C-1-E-100-B-10S

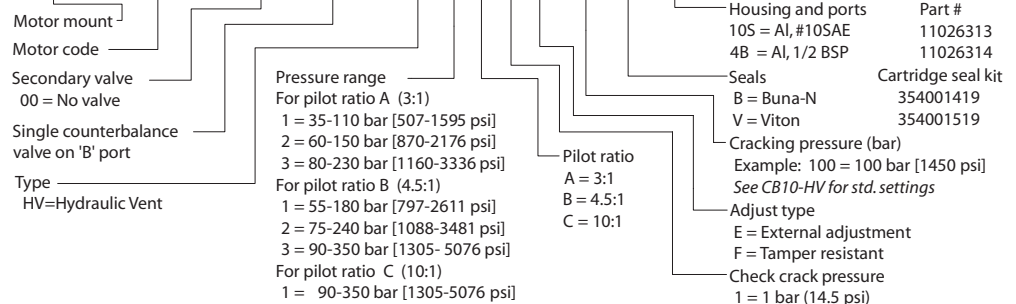

MM - Motor Mount HICs Catalog
 MM-OMP/OMR-00-BCB10-HV