


OPERATION


This is a dual cross-port relief HIC that mounts to OMP/OMR motors with BSP porting.

Schematic

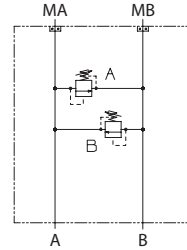

SPECIFICATIONS

Theoretical performance

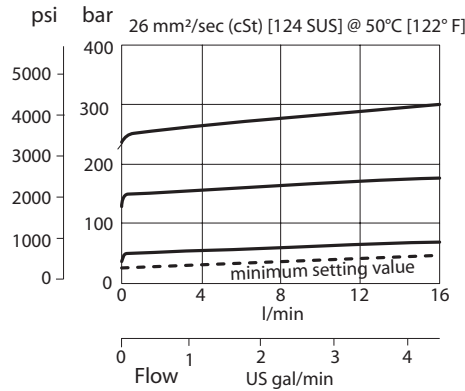


Specifications

Rated pressure	210 bar [3045 psi]
Rated flow at 7 bar [102 psi]	40 l/min [11 US gal/min]
Weight	1.14 kg [2.51 lb]
Cartridge	VME 06
Service mount kit	11023868
Motor	OMP/OMR

DIMENSIONS

Cross-sectional view

mm [in]

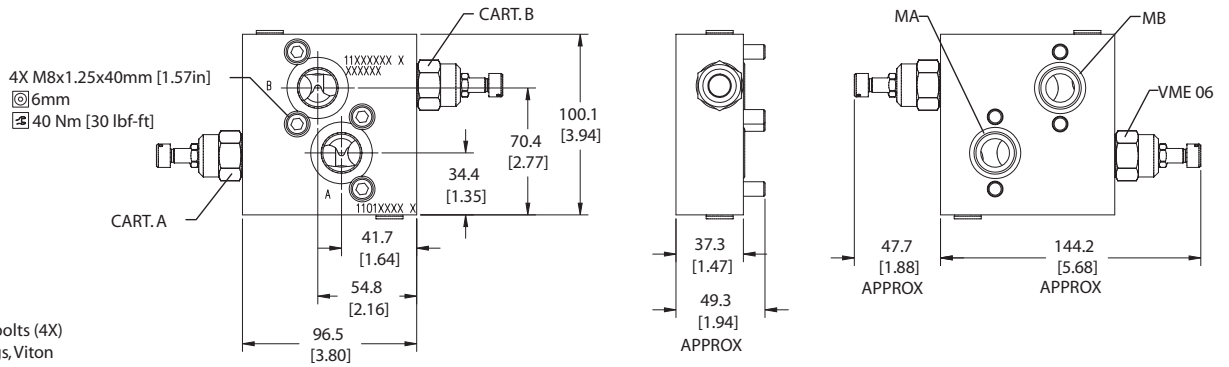

HIC Includes:
 - M8x40mm bolts (4X)
 - (-119) O'rings, Viton (23.47x2.62 mm) (2X)

ORDERING INFORMATION

MM-OMP/OMR-00-DVME06-EN-2-10S-B-100

