


**OPERATION**


This is a single cross-port relief (A to B) HIC that mounts to OMP/OMR motors with BSP porting.

**Schematic**

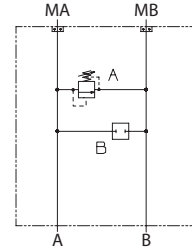

**SPECIFICATIONS**

**Theoretical performance**

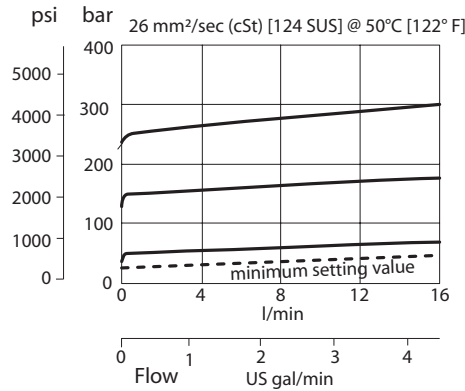

**Specifications**


Rated pressure	210 bar [3045 psi]
Rated flow at 7 bar [102 psi]	40 l/min [11 US gal/min]
Weight	1.14 kg [2.51 lb]
Cartridge	VME 06
Plug	11026074
Service mount kit	11023868
Motor	OMP/OMR

**DIMENSIONS**


**Cross-sectional view**

mm [in]

- 4X M8x1.25x40mm [1.57in]
- ⊙6mm
- ⊞40 Nm [30 lbf-ft]

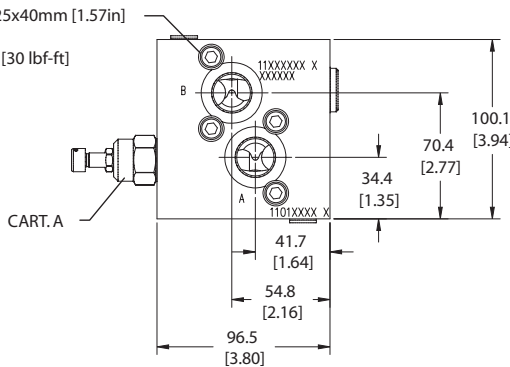

- HIC Includes:
- M8x40mm bolts (4X)
  - (-119) O'rings, Viton (23.47x2.62 mm) (2X)

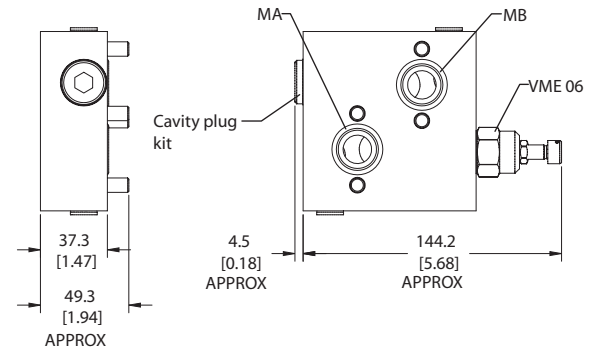

**ORDERING INFORMATION**

**MM-OMP/OMR-00-AVME06-EN-2-10S-B-100**

