
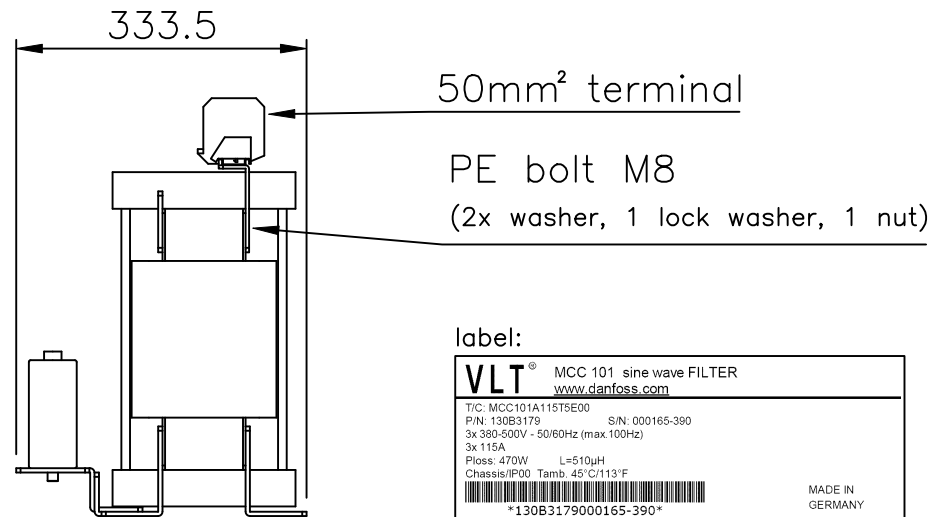




additional informations:

filter colour : impregnated
 filter weight : 95kg

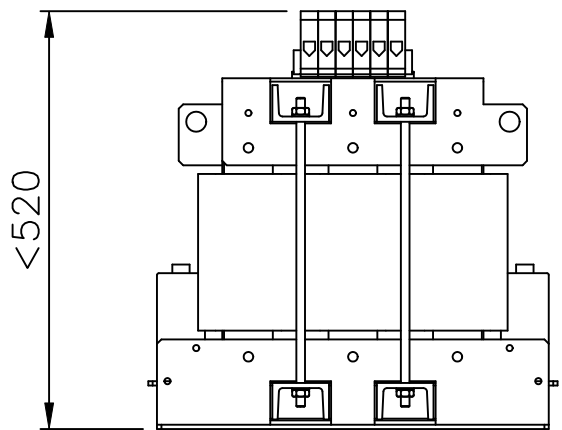

label:

VLT ® MCC 101 sine wave FILTER	
www.danfoss.com	
T/C: MCC101A115T5E00	S/N: 000165-380
P/N: 130B3179	3x 380-500V - 50/60Hz (max. 100Hz)
3x 115A	L=510µH
Chassis/IP00 Tamb. 45°C/113°F	
130B3179000165-390	
E 218022 Ins. Conf. Eq. ta(max)=40°C	B 1001072 FA-Nr.: 000000
MADE IN GERMANY	
VDE 0570 EN 61558	

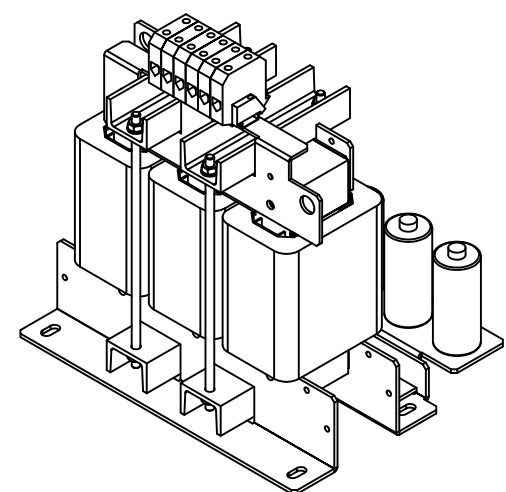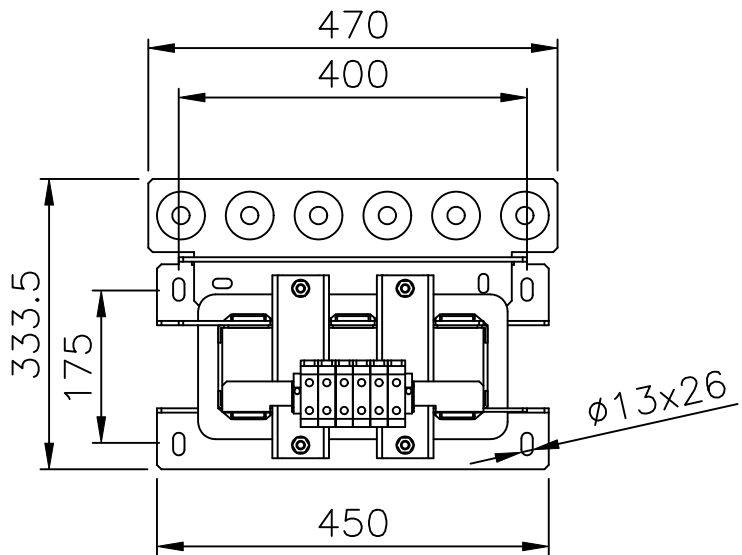

a	30.09.10	KOR/Lauer	approval added
	date	name	amendment

Dimensions toleranced according to ISO 2768-m						
Tolerance class	0.5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400	from 400 to 1000
m (middle)	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8

drawn	01.06.10	Kornau	Kornau	scale	/
checked	01.06.10	Bremer	Bremer	format	
	date	name	signature	DIN ISO 5456	
				all dimensions mm	

Dimensions B 1001072					
sine-wave filter 500V 115A - IP00					
order number	130B3179	drawing number	Z791004002	modi.	sheet
				a	1/1
Please observe protection clause to DIN 34					