
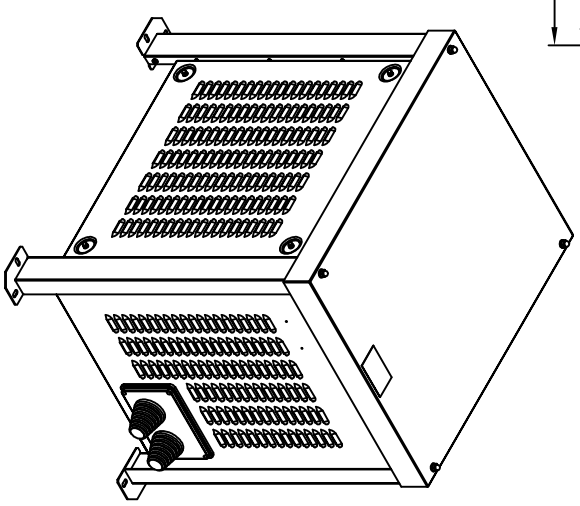
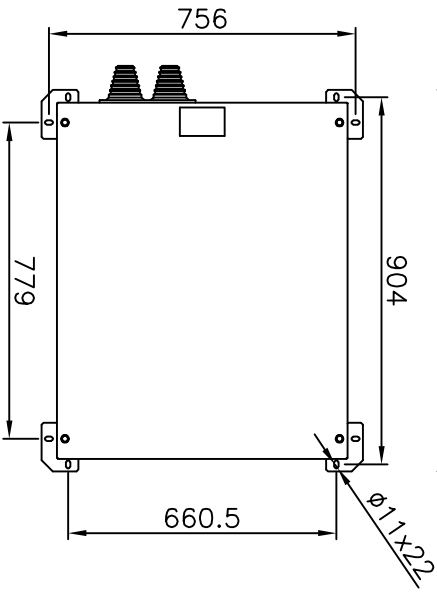


additional informations:
 filter colour : RAL5008 / R9006
 filter weight : 205kg

label:

VLT MCC 101 sine wave FILTER		License 453-3430 Vording Denmark	
www.danfoss.com		MADE IN GERMANY	
T/C: MCC101A15TE2BE S/N: C00162-176		C=43-F	
3x386-500V 50/60Hz (max 100Hz)		I=3kVA	
3x115-450Hz 109A@0Hz 86A@100Hz		F=55-70V	
NEMA 1/P23 Term. 45 C@115 F		T=100mm	
130B318100159-175		Terminal 2x5-50mm only CU	
E27022 1HD		EN 61538	
UL E27022 1HD		CE	
See manual for installation			

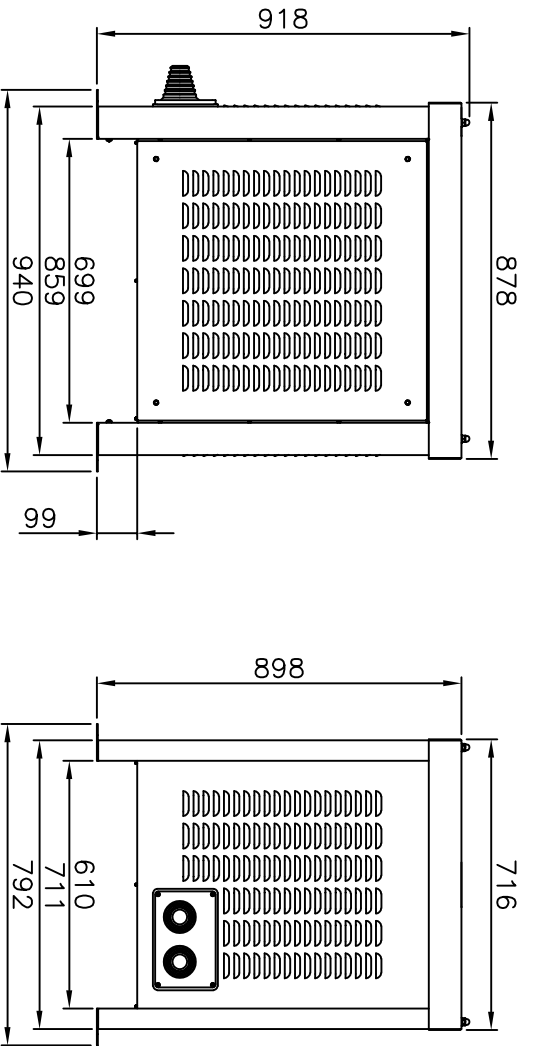

Dimensions B 1001072.2
 sine-wave filter 500V 115A – IP23

e	25.04.16	Schrö./Fle.	typelabel updated
d	05.11.14	Schrö./Fle.	Danfoss Postaddress Included typelabel updated
c	06.03.13	Schrö./Kor.	typelabel updated
b	06.03.13	Schrö./Kor.	typelabel updated
a	30.09.10	KOR/Lauer	approval added
		date	name amendment

Dimensions toleranced according to ISO 2768-m						
Tolerance class	0,5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400	from 400 to 1000
m (middle)	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8

drawn	01.06.10	Kornau	Kornau	scale	1:1.5
checked	01.06.10	Bremer	Bremer	format	A4
	date	name	signature		



dll dimensions mm

order number	130B3181	drawing number	Z791004026	modi.	e	sheet	1/1
Please observe protection clause to ISO 16016							