
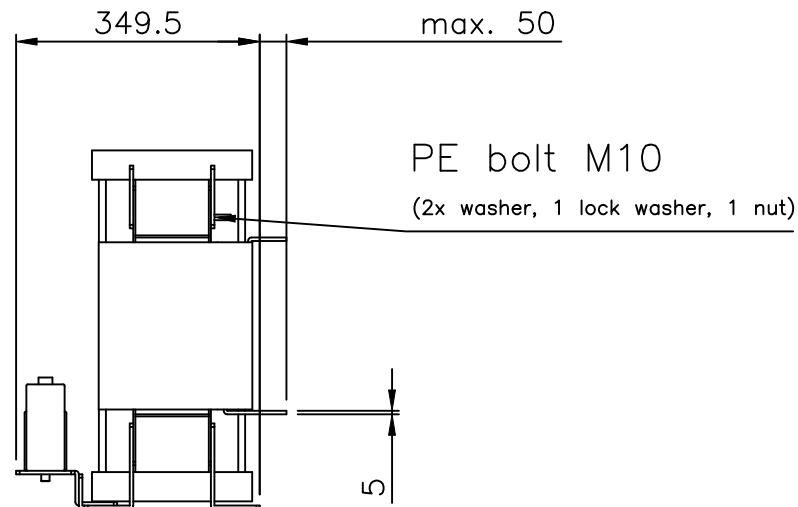



additional informations:

filter colour : impregnated
 filter weight : 197kg


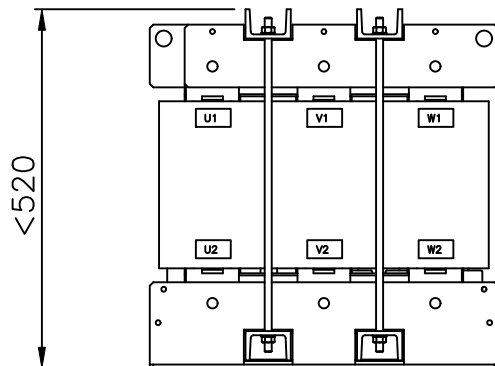


label:

VLT MCC 101 sine wave FILTER www.danfoss.com	
T/C: MCC101A260T5E00	S/N: 000166-390
P/N: 130B3184	3x 380-500V - 50/60Hz (max.100Hz)
3x 260A	Loss: 850W L=340μH
Chassis/IP00 Tamb 45°C/113°F	MADE IN GERMANY
130B3184000166-390	
LISTED E 219022 UL US Ind. Cont. Eq.	B 1001074 FA-Nr.: 000000 VDE 0570 EN 61556 CE

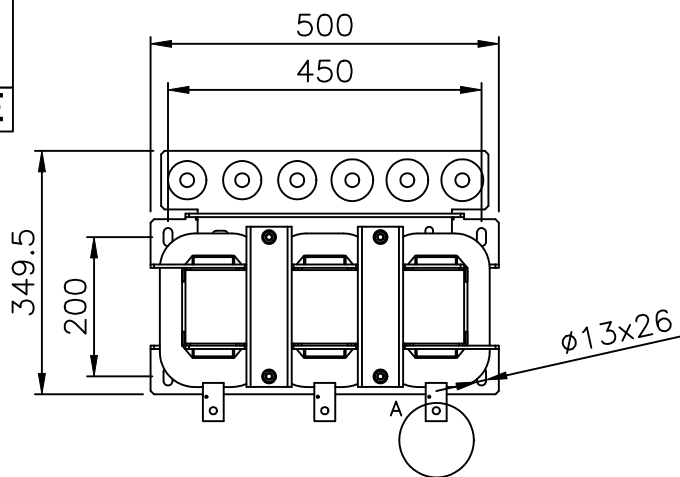

Detail A:
scale 3:1

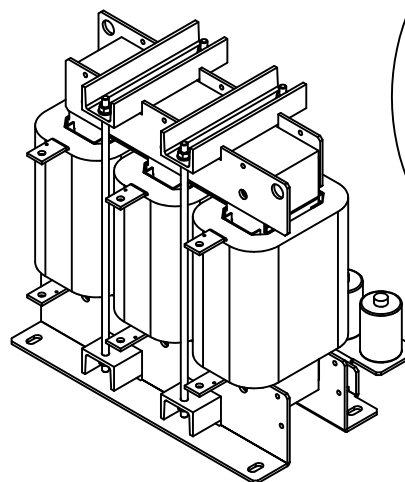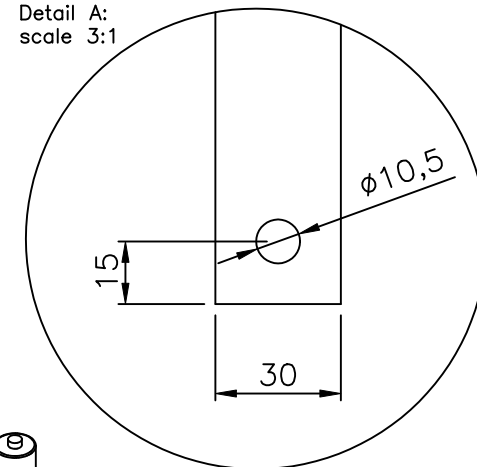

b	30.09.10	KOR/Lauer	approval added
a	01.06.10	KOR/BRE	new mechanical design
	date	name	amendment

Dimensions toleranced according to ISO 2768-m						
Tolerance class	0.5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400	from 400 to 1000
m (middle)	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8

drawn	12.04.10	Kornau	Kornau	scale
checked	12.04.10	Bremer	Bremer	format
	date	name	signature	A4
				DIN ISO 5456
all dimensions mm				

Dimensions B 1001074
 sine-wave filter 500V 260A - IP00

order number	drawing number	modi.	sheet
130B3184	Z791004004	b	1/1

Please observe protection clause to DIN 34