
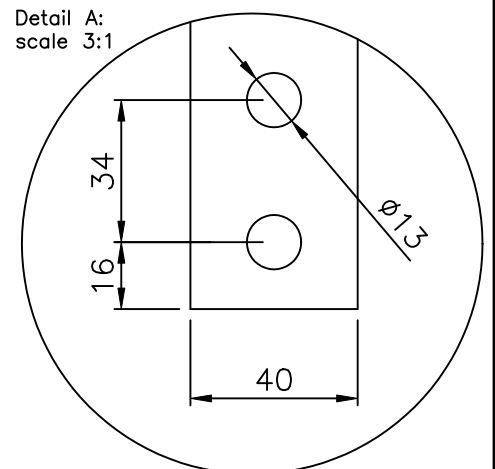
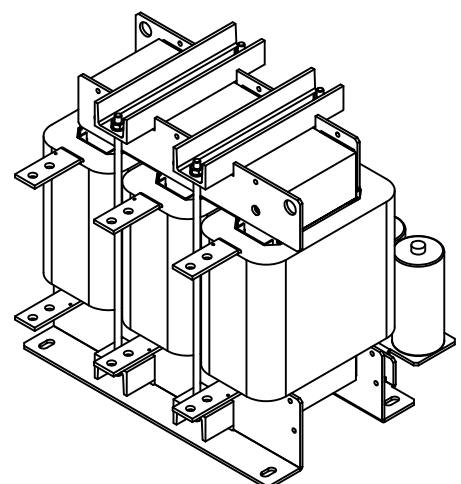
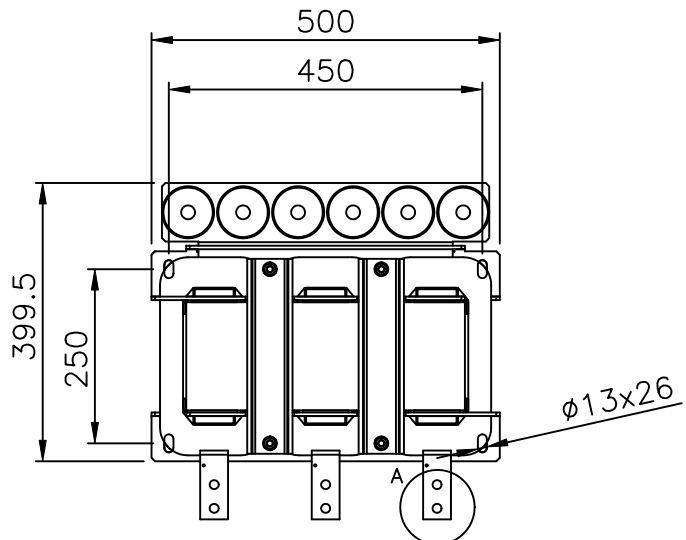
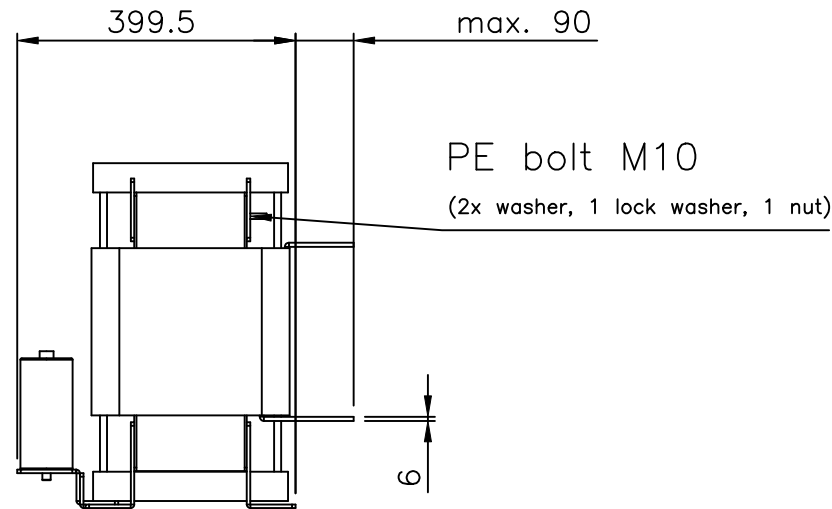


additional informations:

filter colour : impregnated
 filter weight : 265kg

label:

VLT ® MCC 101 sine wave FILTER www.danfoss.com	
T/C: MCC101A510T5E00	S/N: 000165-390
P/N: 130B3188	3x 380-500V - 50/60Hz (max.100Hz)
3x 510A	L=140µH
Class: 1450W	Chassis/IP00 Tamb. 45°C/113°F
MADE IN GERMANY	
130B3188000165-390	
E 219022 UL US Ind. Cont. Eq.	B 1001076 FA-Nr.: 000000
VDE 0570 EN 61558	CE

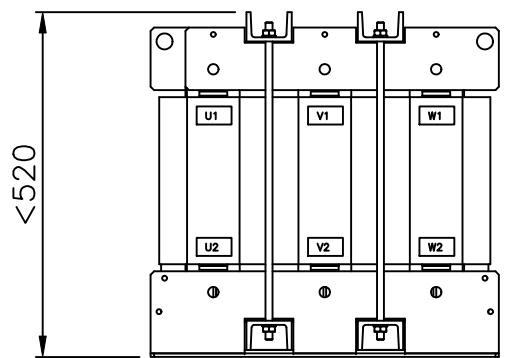

a	30.09.10	KOR/Lauer	approval added
	date	name	amendment

Dimensions toleranced according to ISO 2768-m						
Tolerance class	0.5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400	from 400 to 1000
m (middle)	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8

drawn	01.06.10	Kornau	Kornau	scale
checked	01.06.10	Bremer	Bremer	formate
	date	name	signature	A4
				DIN ISO 5456
				all dimensions mm

Dimensions B 1001076				
sine-wave filter 500V 510A - IP00				
order number	130B3188	drawing number	Z791004006	modi.
				a
sheet	1/1	Please observe protection clause to DIN 34		