
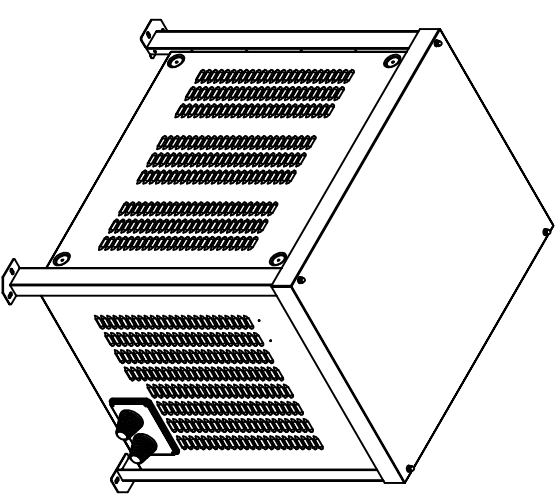
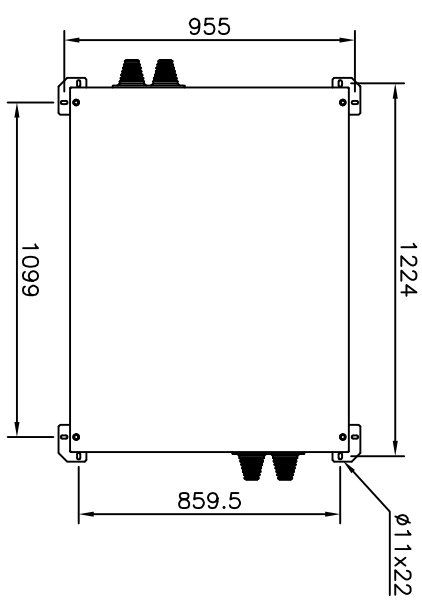


additional informations:
 filter colour : RAL5008 / R9006
 filter weight : 610kg

label:

 MCC 101 sine wave FILTER www.danfloss.com		Danfloss A/S, 6430 Nordby, Denmark MADE IN GERMANY	
TIC: MCC101A90078E238 PIN: 1308314		SIN: 000189-188 CY: 4556	
3x 380-500V - 50/60Hz (max 100-Hz) 3x 800A @ 50Hz 738k @ 60Hz 631A @ 50Hz		2-pole 24kV 2-pole 24kV Voltage: 81 000 Tightening torque 30Nm	
NEBA 11723 1mm 55x115		*1308314C00169-186* Use only with a type 1 or type 2 SPD overvoltage control device	
 E21022 1000V 1000V 1000V		 E1001078.2 FA-NC: 000000 EN 61556	

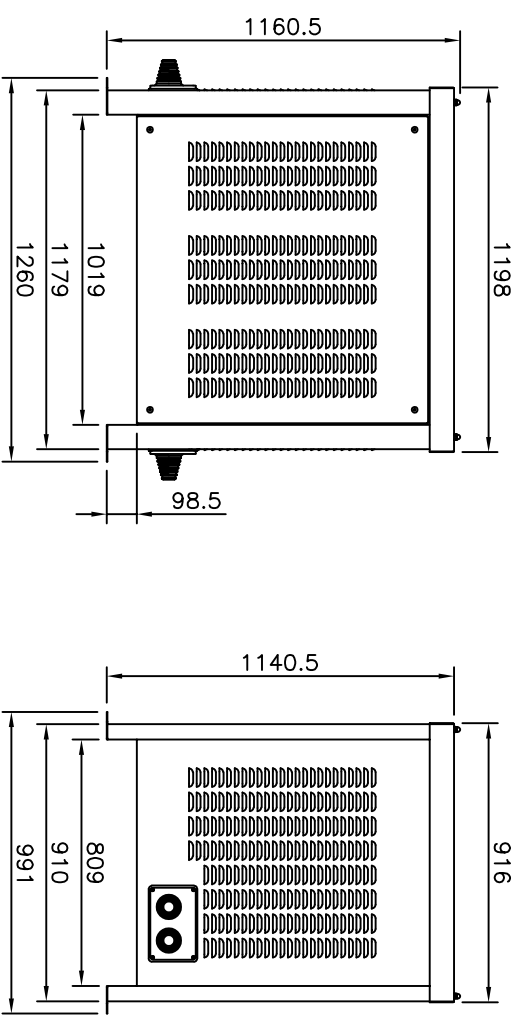

e 03.05.16	Schr./File.	typelabel updated
d 01.11.14	Schr./File.	Danfloss Postaddress Included typelabel updated
c 10.04.13	Schr./Kor.	typelabel updated
b 11.03.13	Schr./Kor.	typelabel updated
a 01.10.10	KOR/Lauer	approval added
date	name	amendment

Dimensions toleranced according to ISO 2768-m						
Tolerance class	0.5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400	from 400 to 1000
m (middle)	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8

drawn	01.06.10	Korrau	Korrau	scale	1:20
checked	01.06.10	Bremer	Bremer	formate	A4
date			signature		

Dimensions B 1001078.2
 sine-wave filter 500V 800A – IP23

order number 130B3194
 drawing number Z791004032
 mod.: e
 sheet 1/1

Please observe protection clause to ISO 16016

1 2 3 4 5 6 7 8