





additional informations:
 filter colour : RAL5008 / R9006
 filter weight : 645kg

label:

VLT MCC 101 sine wave FILTER
 www.danfoss.com Danfoss A/S, 2450 Rendboj, Denmark

TYPE: MCC101S430V F230E S/N: 000163-188
 FIN: 130B4153 3x 525-690V 50/60Hz max. 100Hz L=230mm
 3x 420/495/570 40/24/25Hz 322A@100Hz CV=120kV
 I=100A I=175A I=180A 270V@110Hz Weight: 645kg
 130B4153000163-159 Tilt: 10°
 Use with 30A breaker for type 322A overcurrent limited device
 EN 61559

UL 1008 Safety Standard for Type I II III
 IEC 60384-14 Safety Standard for Type I II III
 CE

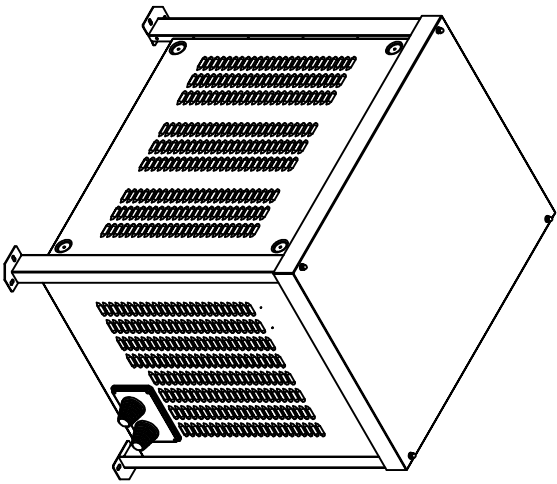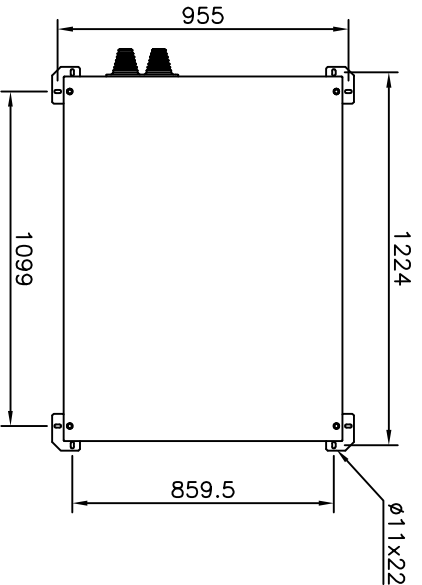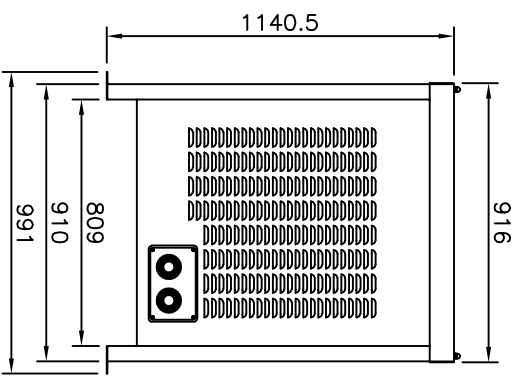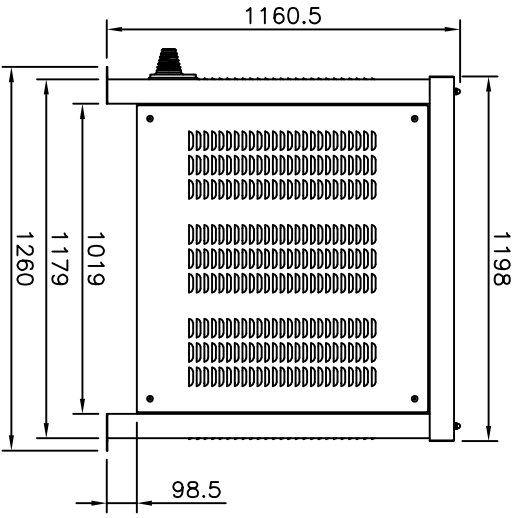

e 09.05.16	Schr./Fle.	typelabel updated, Danfoss Postaddress included
d 17.11.14	Schr./Fle.	typelabel updated
c 11.03.13	Schr./Kor.	typelabel updated
b 11.03.13	Schr./Kor.	typelabel updated
a 01.10.10	KOR/ Laufer	approval added
date	name	amendment

Dimensions toleranced according to ISO 2768-m						
Tolerance class	0.5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400	from 400 to 1000
m (middle)	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8

drawn	01.06.10	Korrau	Korrau	scale	1:20
checked	01.06.10	Bremer	Bremer	format	A4
date		name	signature	DIN ISO 5456	

Dimensions B 1002057.2
 sine-wave filter 690V 430A – IP23

order number	130B4153	drawing number	Z791004041	modi.	e	sheet	1/1
--------------	----------	----------------	------------	-------	---	-------	-----

Please observe protection clause to ISO 16016