










additional informations:

filter colour : RAL7001
 filter weight : 124kg

label:


VLT MCC 101 sine wave FILTER		Danfoss A/S, 6430 Nordborg, Denmark	
www.danfoss.com			
T/C: MCC101A115T3L23B	SN: 000168-176	MADE IN GERMANY	
PN: 130B5479		L=510µH	Cy=45µF
3x 380-500V - 50/60Hz (max.100Hz)		fsw=3kHz	Ploss= 470W
3x 115A@50Hz 109A@60Hz 86A@100Hz		Weight: 124kg	Tightening torque terminal: 2,0-6,0Nm only CU
NEMA 1/IP23 Tamb. 45°C/113°F			
			
130B5479000168-176			
Use only with a type 1 or type 2 SPD overvoltage control device			
	E 219022 Ind. Cont. Eq. 1HD1 Ia(max)=40°C		B 1001072.1 FA-Nr.: 000000 See manual for UL-requirements
		EN 61558	

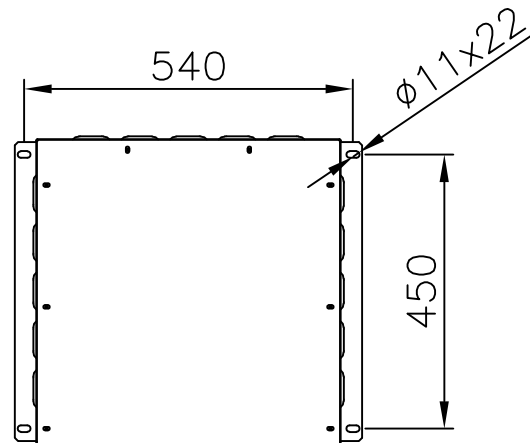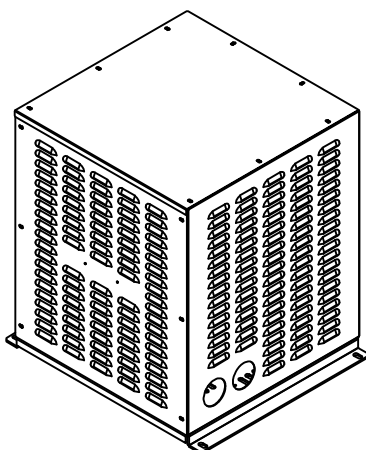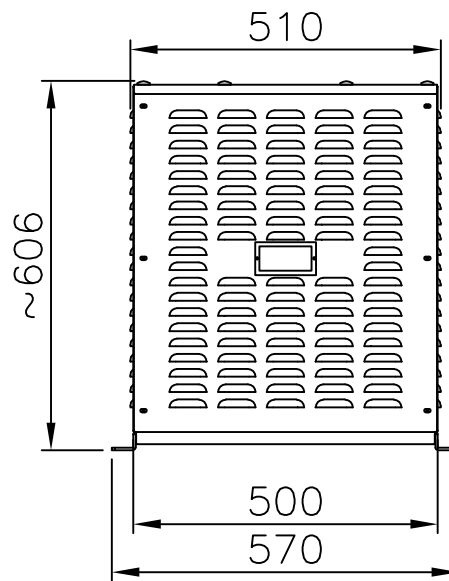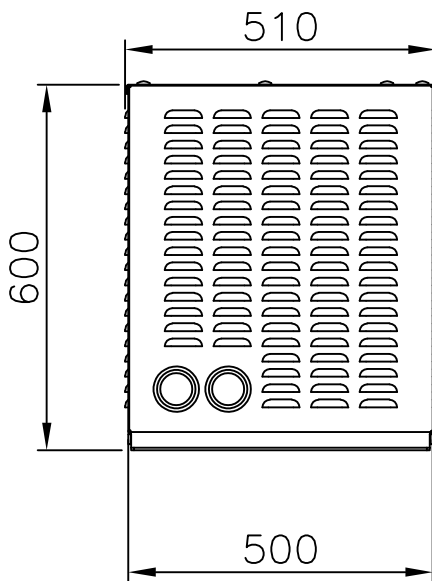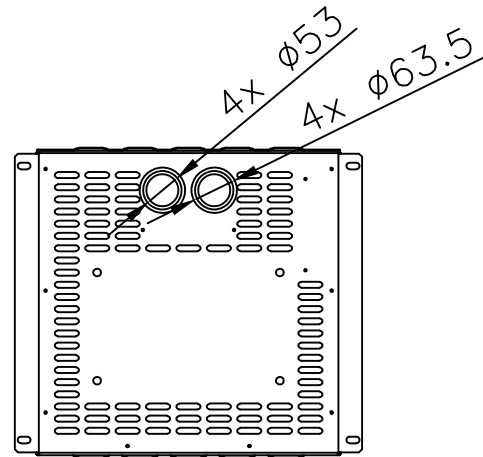

d	25.04.16	Schrö./Fl.	typelabel updated, Danfoss Postaddress included
c	21.06.15	Schrö./Fl.	typelabel updated
b	05.11.14	Schrö./Fl.	typelabel updated
a	06.03.13	Schrö./Kor.	typelabel updated
	date	name	amendment

drawn	06.10.11	Kornau	Kornau	scale
checked	06.10.11	Bremer	Bremer	1:10
	date	name	signature	format
				A4

Dimensions B 1001072.1
 sine-wave filter 500V 115A – IP23s

DIN ISO 5456	order number	drawing number	modi.	sheet
	130B5479	Z791110001	d	1/1

all dimensions mm Please observe protection clause to ISO 16016