
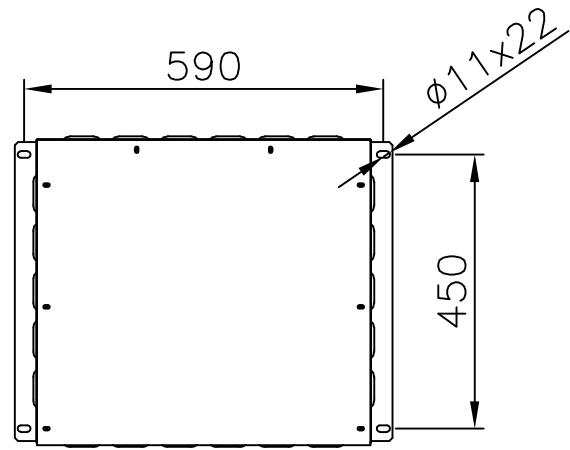
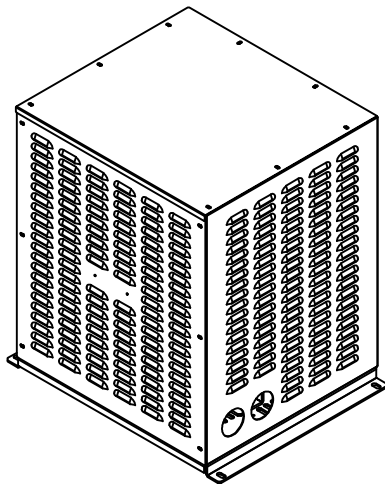
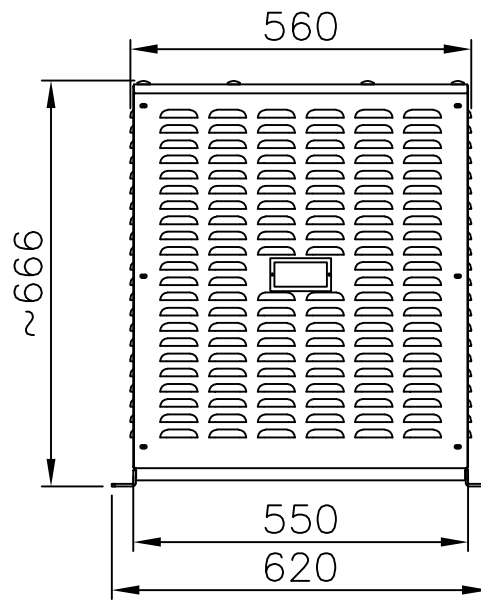
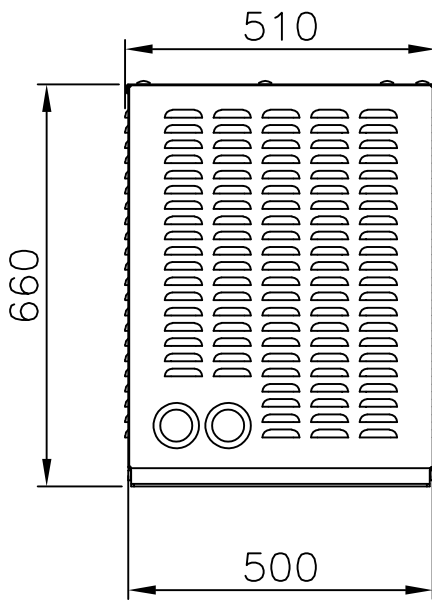


additional informations:

filter colour : RAL7001
 filter weight : 159kg

label:


VLT MCC 101 sine wave FILTER		Danfoss A/S, 6430 Nordborg, Denmark	
www.danfoss.com		MADE IN GERMANY	
T/C: MCC101A180T3L23B	S/N: 000169-176	L=330µH	Cy=75µF
P/N: 130B5480		fs=3kHz	Ploss: 650W
3x 380-500V - 50/60Hz (max:100Hz)		Weight: 159kg	Tightening torque
3x 180A@50Hz 170A@60Hz 135A@100Hz		terminal: 12,0-20,0Nm	only CU
NEMA 1/IP23 Tamb. 45°C/113°F			
130B5480000169-176			
Use only with a type 1 or type 2 SPD overvoltage control device			
	E 219022 Ind. Cont. Eq. 1HD1 Ia(max)=40°C	B 1001073.1 See manual for UL-requirements	FA-Nr.: 000000 EN 61558

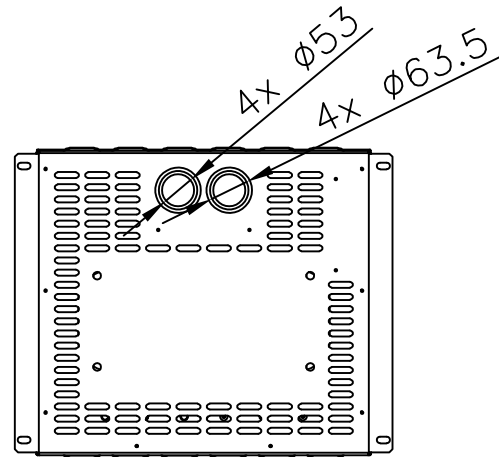

e	25.04.16	Schr./Fl.	typelabel updated, Danfoss Postaddress included
d	20.06.15	Schr./Fl.	typelabel updated
c	05.11.14	Schr./Fl.	typelabel updated
b	27.01.14	KOR / Fl.	terminal torque updated
	date	name	amendment

drawn	06.10.11	Kornau	Kornau	scale
				1:10
checked	06.10.11	Bremer	Bremer	format
				A4
	date	name	signature	

 Dimensions B 1001073.1
 sine-wave filter 500V 180A – IP23s



order number	drawing number	modi.	sheet
130B5480	Z791110002	e	1/1

all dimensions mm

Please observe protection clause to ISO 16016