

 
additional informations:
 filter colour : RAL7001
 filter weight : 12,9kg
 cable clamp : 2x 195N3206

label:

VLT ® MOC 101 sine wave FILTER		MADE IN GERMANY
www.danfoss.com		C/3 3UF
TC: MOC101A10K7TE208 S.N.:00148-083		fsw=4kHz
P/N: 130B7324		Weight: 129kg
3x 525-690V -50/60Hz (max. 100Hz)		Tightening torque
3x 10A		terminal 0,5-1,0Nm
Chassis/IP20 Tamb: 45°C/113°F		
130B7324000148-083		
B 1212047.1	F.A.N.:000000	EN 61558
		CE

Dimensions toleranced according to ISO 2768-m							
Tolerance class	0,5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400	from 400 to 1000	
	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8	
m (middle)							

drawn	19.02.13	Kornau	Kornau	scale	1:4
checked	19.02.13	Bremer	Bremer	formate	A4
date		name	signature		







all dimensions mm

Dimensions B 1212047.1
 sine wave filter 690V 10A – IP20

order number 130B7324 drawing number Z791302004 mod: 0 sheet 1/2

Please observe protection clause to ISO 16016

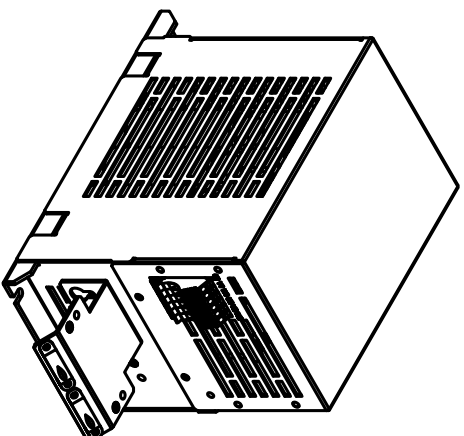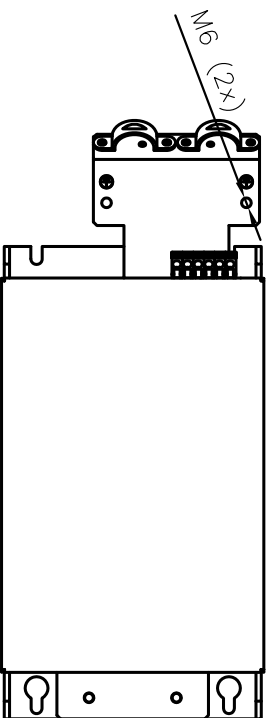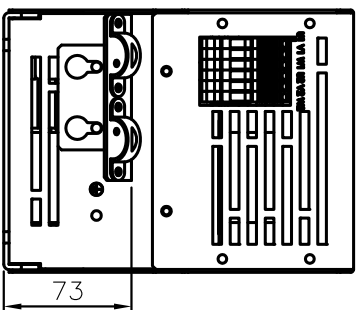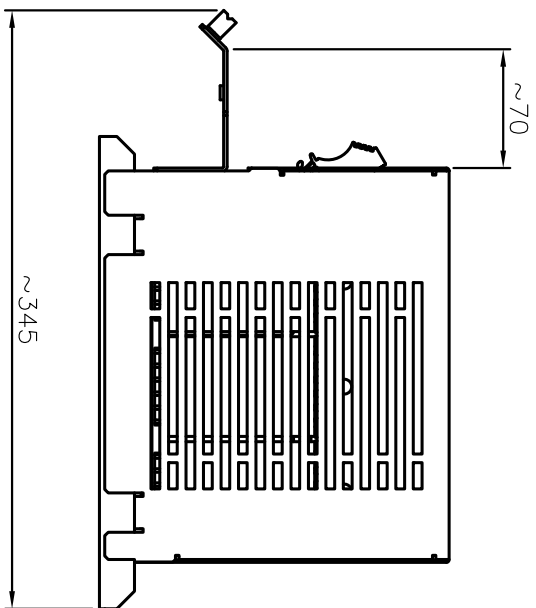

included accessories
(screen connection plate)

Dimensions toleranced according to ISO 2768-m			
Tolerance class	0,5 to 3	from 3 to 6	from 6 to 30
m (middle)	±0.1	±0.1	±0.2
			from 30 to 120
			from 120 to 400
			from 400 to 1000
			±0.5
			±0.8

drawn	19.02.13	Kornau	Kornau	scale	1:4
checked	19.02.13	Bremer	Bremer	format	A4
	date	name	signature		
				DIN ISO 5456	
				all dimensions mm	
order number			130B7324	drawing number	
drawing number			Z791302004	modi.	
Please observe protection clause to ISO 16016			0	sheet	
				2/2	

Dimensions B 1212047.1
sine wave filter 690V 10A – IP20

1 2 3 4 5 6 7 8

1

2

3

4

5

6

7

8

F

E

D

C

B

A

F

E

D

C

B

A