
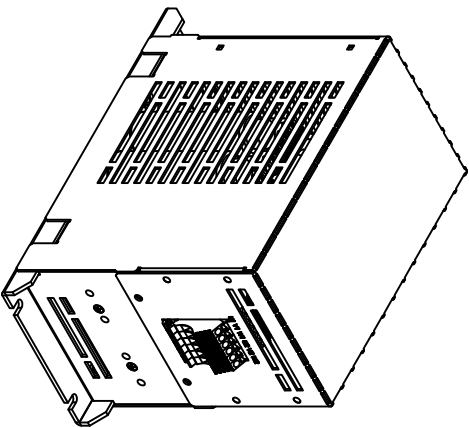


additional informations:
 filter colour : RAL7001
 filter weight : 9,0kg
 cable clamp : 2x 195N3206

Label:

VLT MCC 101 sine wave FILTER www.danfoss.com		L=18mm Cj=2µF Isv=4kHz
TTC: MCC101AKST7E20B S/N: 000165-212		Tightening torque
P/N: 130B7356		terminal 0.5-1.0mm
3x 32x4680V - 50/60Hz (max.100Hz)		MADE IN GERMANY
Phase: 80V		
Chassis/IP20 Temp: 45°C/131°F		
130B7356000165-212		
B 1201009 1	FA-N.: 000000	EN 61558
		CE

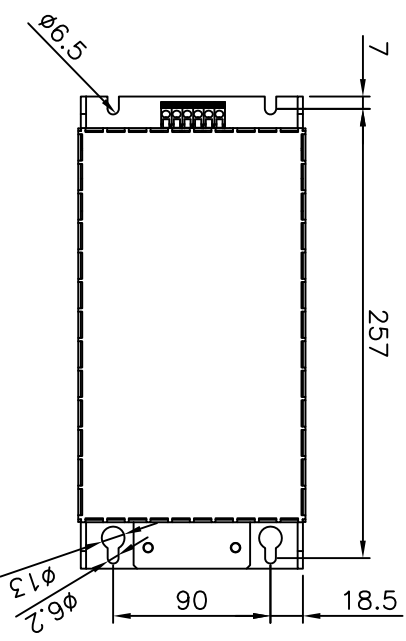

Dimensions toleranced according to ISO 2768-m						
Tolerance class	0,5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400	from 400 to 1000
m (middle)	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8





drawn	22.05.12	Kornau	Kornau	scale	1:4
checked	22.05.12	Bremer	Bremer	format	A4
date		name	signature	DIN ISO 5456	

Dimensions B 1201009.1
 sine wave filter 690V 4,5A – IP20

order number	130B7356	drawing number	Z791205007	modi.	0	sheet	1/2
--------------	----------	----------------	------------	-------	---	-------	-----


Please observe protection clause to ISO 16016

included accessories
(screen connection plate)

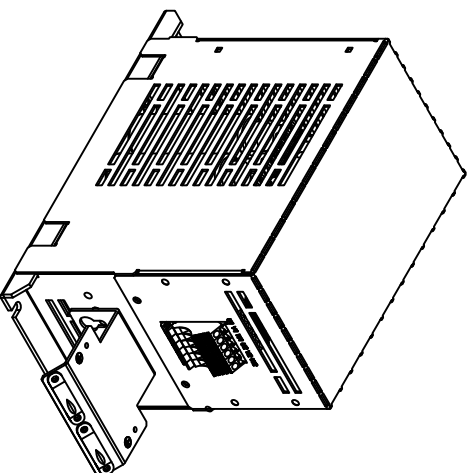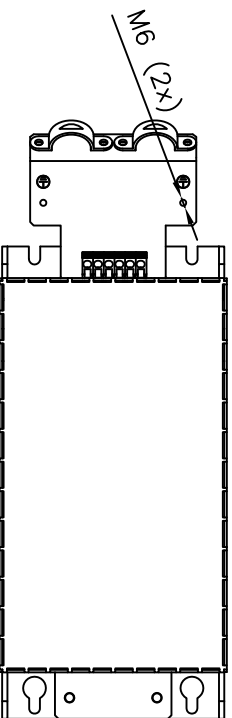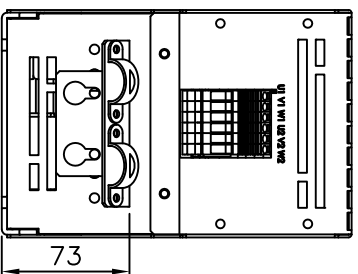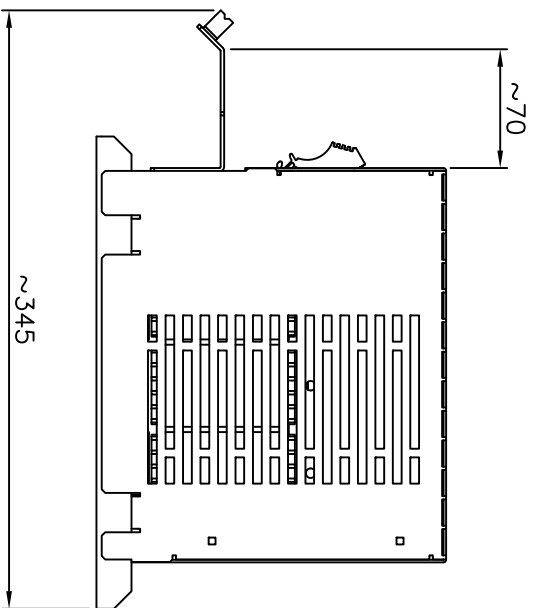

Dimensions toleranced according to ISO 2768-m			
Tolerance class	0,5 to 3	from 3 to 6	from 6 to 30
m (middle)	±0.1	±0.1	±0.2
		from 30 to 120	from 120 to 400
		±0.3	±0.5
			from 400 to 1000
			±0.8

drawn	22.05.12	Kornau	Kornau	scale	1:4
checked	22.05.12	Bremer	Bremer	format	A4
	date	name	signature		

 

all dimensions mm

Dimensions B 1201009.1
sine wave filter 690V 4,5A – IP20

order number	130B7356	drawing number	Z791205007	modi.	0	sheet	2/2
--------------	----------	----------------	------------	-------	---	-------	-----

Please observe protection clause to ISO 16016