
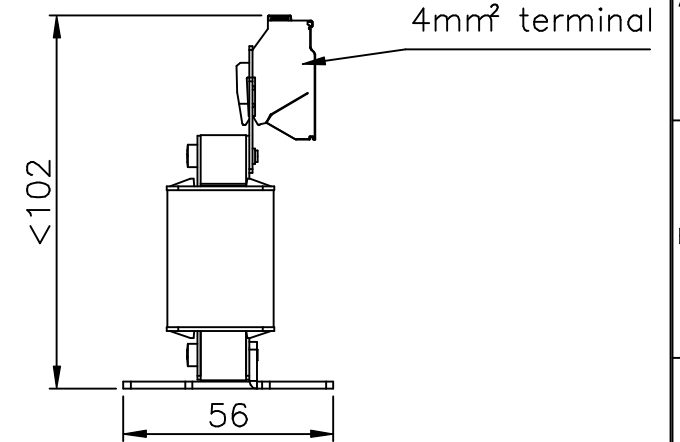




additional informations:

Inductance : 3,2mH
 Rated current : 2,3A
 Rated voltage : 3x 500V
 Ambient temperature : max. 45°C

earth terminal
 6.3x0.8 faston

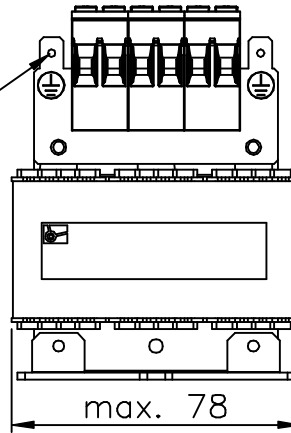

label:

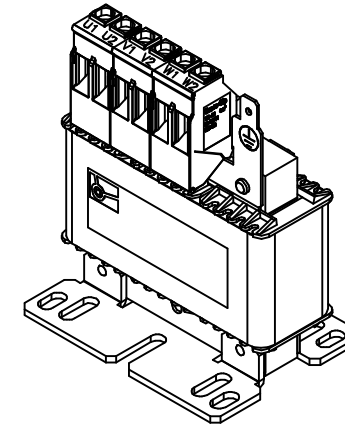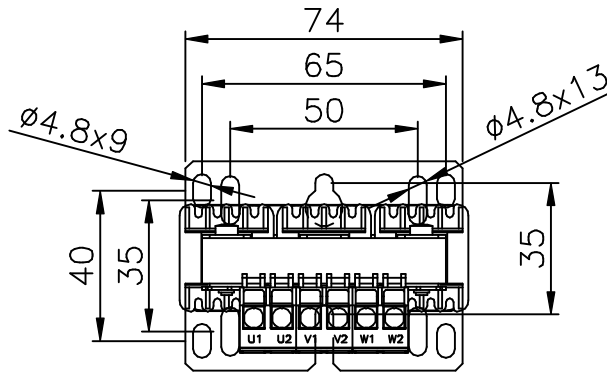

b	10.02.14	Schr./ Fle.	order number and MCC number changed
a	14.02.13	Schr./ Kor.	label updated, Terminalmarking included
	date	name	amendment

drawn	17.10.12	Kornau	Kornau	scale	1:2
checked	18.10.12	Lauer	Lauer	format	A4
	date	name	signature		
				DIN ISO 5456	
				all dimensions mm	

Dimensions B 1101131
 Line Reactor LR3/x 2,3A – IP00

Dimensions toleranced according to ISO 2768-m						
Tolerance class	0,5 to 3	3 to 6	6 to 30	30 to 120	120 to 400	400 to 1000
m (middle)	±0.1	±0.1	±0.2	±0.3	±0.5	±0.8

order number	drawing number	modi.	sheet
175U0296	Z791210002	b	1/1

Please observe protection clause to ISO 16016