


**output terminals**  
 U2, V2, W2: 95mm<sup>2</sup>  
 Tightening torque: 6.0-12.0Nm

**input terminals**  
 U1, V1, W1, R+: 35mm<sup>2</sup>  
 Tightening torque: 2.5-5.0Nm

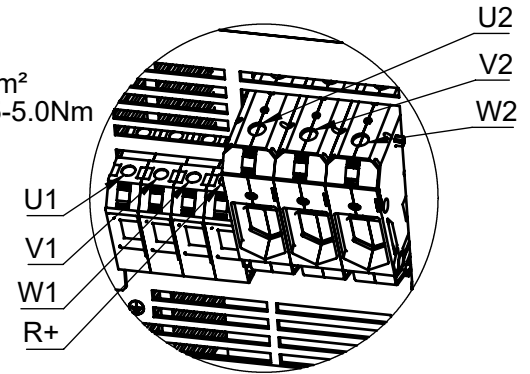

A (1 : 3.5)

Cable clamp PUK 24B  
 Danfoss part-No. 175Z1756  
 Cable clamp PUK 52B

- included accessories**
- 1x decoupling plate
  - 1x cable clamp PUK 24B
  - 1x cable clamp PUK 52B
  - 2x cable clamps R=35
  - 4x screws M4x25
  - 2x combi-screws M6x16
  - 4x screws M5x8

Surface filter color RAL 7001				Weight 43.4kg		MCC201A43KT3E20B	
C	30.10.2020	Besbes	312236	Scale 1:7	All Mode Sine-Wave Filter 46A 400V IP20		
B	06.10.2020	Besbes	306597				
Rev	Date	Name	Modification				
Cons.	30.10.2020	Besbes	General tolerance ISO 2768-mK	Order number 175U6046	Drawing Number-Revision-Version 213616-C-0		
Draw.	30.10.2020	Besbes	ISO 5456				
Check.	30.10.2020	Eilers					

Order number 175U6046		Drawing Number-Revision-Version 213616-C-0	
Observe protection clause to ISO 16016			Sheetsize A4
			Sheet 1/1

