

 

-T1
/2.5:8



VLT FC302 I/O CARD



DISPLAY

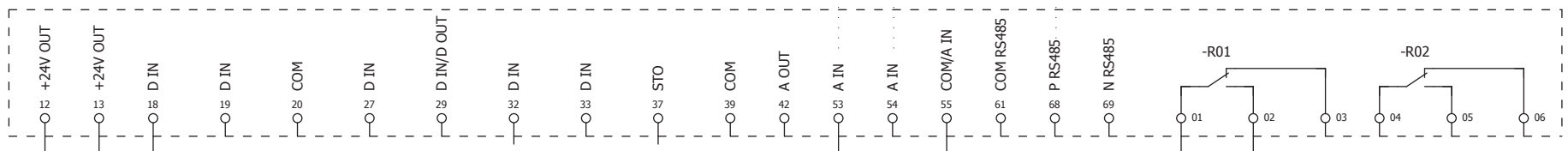

8.5:E U1-32
8.5:E U1-37

* Set point
Sollwert

Drive signal start active
FU Signal Start aktiv

Parameter list

| Parameter | Description Beschreibung | Value Wert |
|-----------|-----------------------------|---------------|
| 5-40 | Ready | 2 |
| 5-12 | Without function | 0 |

* Current input, 0-20mA and 4-20mA
Stromeingang, 0-20 mA und 4-20 mA
Voltage input, -10 - +10 V DC
Spannungseingang -10 - +10 V DC

| Modification | Date | Name | Contr. |
|--------------|------|------|--------|
| | | | |

| Date | 9/30/2013 |
|--------|-----------|
| Ed. | ---- |
| Appr | ---- |
| Contr. | ---- |

Commission
110KW VFD Panel
Project description
Disconnect switch+Fuse+dudt Filter
Trennschalter+Sicherung+dudt Filter

Danfoss GmbH
VLT Drives EMA, Carl-Legien Strasse 8
63073 Offenbach, Germany



FILE-NAME:
LOG08300.jpg
Size 300px x 116px

Page description
Frequency converter
Frequenzumrichter

Project Number

SAP NO

= FC302
+ N110KW 230V
Manufacturer no